


RG20P Series

Centrifugal Blower

Ø 200mm

- AC single inlet, forward curved centrifugal blower in standard housing. The integrated external-rotor motor is mounted inside the housing.
- Housing and impeller made of galvanized sheet-steel. Forward curved impellers are directly press-fitted onto the rotor of the external-rotor motor.
- Direction of rotation is CW as seen from inlet side. Insulation class "F".
- Maintenance-free ball bearings.
- UL, CSA, VDE approvals on some models, please contact application engineering.

Part Number	Curve	CFM @ Q	VAC	Hertz	Power (W)	dBA	Max Amb. Temp C	Bearing Type	Features	Capacitor (µF)	Wgt. (lbs)
RG20P-4/106478	1	700	115	60	410	83	40	Ball	Leads	16	22.0
RG20P-4/106479	1	700	230	60	380	83	40	Ball	Leads	4	22.0

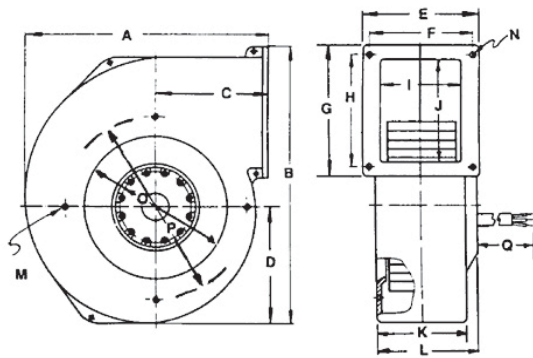

DIMENSIONS - inches (mm)

PART NUMBER	A	B	C	D	E	F	G	H
RG20P	13.46 (342)	16.69 (424)	6.46 (164)	7.13 (181)	7.13 (181)	6.34 (161)	12.05 (306)	11.26 (286)
	I	J	K	L	M	N	Q	
	5.08 (129)	9.96 (253)	5.08 (129)	8.70 (221)	M10	.39 (10)	17.72 (450)	

