

LED EA19-14W1150eGV

Bulb Class: A19

5000K
CCT

Product Description

LED EA19-14W1150eGV replaces conventional 100 Watt incandescent bulbs delivering more brightness (lumens) for less energy (Watts). With lower energy consumption levels you will be able to experience considerable energy savings throughout the years. **EA19-14W1150eGV** design reduces internal bulb heat providing greater durability and constant bulb performance.



Estimated Energy Cost: \$1.68 per year

*Note: Design, features and specifications subject to change without notice. Some features may not be available on all models. Please visit www.eurilighting.com or call 1-310-787-1100 for more information.

Specifications

Input Power	Input Voltage	Lumen Output	Beam Angle	Center Beam	CCT
14 W	120 -277V	1600 lm	210°	N/A	5000 K
CRI	Luminous Efficacy	Power Factor	Input Current	Base	Lamp Lifespan
80	114.3 lm/W	0.7	N/A	GU24	15,000 Hrs.

Product Features



Energy Efficient




Damp Rated



High Output

Product Dimensions

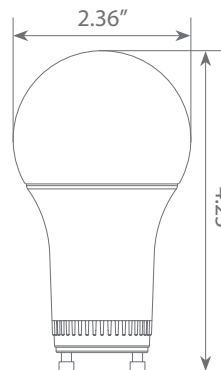

Product Photometric Data

