

LED ECA9.5-2120fcb

Bulb Class: Conical Angle



Product Description

LED ECA9.5-2120fcb is a charming and romantic, this Euri Lighting flickering flame bulb accents and decorates every fixture, from an outdoor lantern to an indoor chandelier. With over 300 programmed LEDs, this long-lasting and energy-efficient flame bulb simulates a natural, flickering flame. Glowing in Candle Light (1800K) color temperature, this decorative flame bulb offers a clear glass lens, flame-shape body and black base – see Euri Lighting ECA9.5-2120fc for white base option.

Enjoy features such as: Energy efficient, wet rated, and animated flame.



Estimated Energy Cost: \$0.12 per year

*Note: Design, features and specifications subject to change without notice. Some features may not be available on all models. For more information please visit: www.eurilighting.com or call 1-888-743-5766

Specifications

Input Power	Input Voltage	Lumen Output	CRI	Beam Angle	Base/Cap	CCT	Lamp Lifespan
1 W	120V/60Hz	80 lm	80	120°	E12	1800 K	15,000 hrs.

Product Features



Energy Efficient



Wet Rated




Animated Flame



Shatter Resistance

Product Dimensions

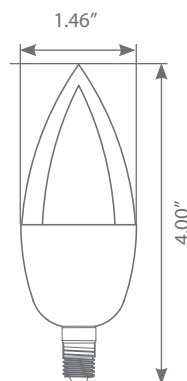

Product Photometric Data

