

# LED EP16-7W4000ew

Bulb Class: PAR16



## Product Description

**LED EP16-7W4000ew** delivers superior brightness, valuable energy savings, and long-lasting performance. This PAR16 LED bulb is ideal for ambient lighting or general-purpose applications due to its uniform \*Soft White Light (3000K) and replaces conventional 50 Watt incandescent light bulbs. Look for EP16-7W4020ew for Warm White (2700K), EP16-7W4040ew for Bright White (4000K) and EP16-7W4050ew for Cool White (5000K).



**Estimated Energy Cost:** \$0.84 per year

\*Note: Design, features and specifications subject to change without notice. Some features may not be available on all models. Please visit [www.eurilighting.com](http://www.eurilighting.com) or call 1-310-787-1100 for more information.

## Specifications

Input Power	Input Voltage	Lumen Output	Beam Angle	Center Beam	CCT
7 W	120V	500 lm	40°	N/A	3000 K

CRI	Luminous Efficacy	Power Factor	Input Current	Base/Cap	Lamp Lifespan
80	71 lm/W	0.7	0.07 A	E26	25,000 Hrs.

### Product Features



Dimmable




Energy Efficient



Damp Rated

### Product Dimensions

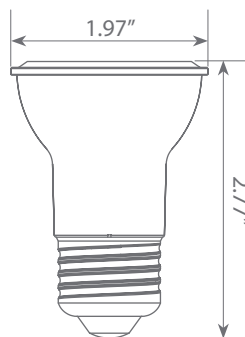

### Product Photometric Data

