

KMK-PA-MB Counternut with collar



KMK-PA-MB

Counternut made of polyamide.
The counternut with collar has a bigger sealing area - sealing with an additional O-ring will be simplified.

Application

- Plant and machine construction
- Automation technology
- Vehicle construction and shipbuilding
- Installation technology
- Control cabinet construction


Material

Polyamide PA 6

- halogen-free
- phosphor-free
- silicone-free
- cadmium-free

Technical data

Temperature range: -40°C up to +100°C

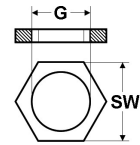

Dimensions

G Thread size inside
SW Spanner size

Metric thread – female

Part no. light grey RAL 7035	Part no. dark grey RAL 7001	Part no. black RAL 9005	Size Metr.	Spanner size mm	Unit	
97816	94260	98163	M12 x 1,5	18	100	-
97817	94261	98164	M16 x 1,5	22	100	-
97818	94262	98165	M20 x 1,5	26	100	-
97819	94263	98166	M25 x 1,5	32	100	-
97820	94264	98167	M32 x 1,5	41	100	-
97821	94265	98168	M40 x 1,5	50	50	-
97822	94266	98169	M50 x 1,5	60	50	-
97823	94267	98170	M63 x 1,5	75	25	-

PG thread – female

Part no. light grey RAL 7035	Part no. dark grey RAL 7001	Part no. black RAL 9005	Size PG	Spanner size mm	Unit	
90710	94250	96458	7	19	100	-
90711	94251	96228	9	22	100	-
90712	94252	96459	11	24	100	-
90713	94253	96460	13,5	27	100	-
90714	94254	96461	16	30	100	-
90715	94255	96176	21	36	100	-
90716	94256	96177	29	46	50	-
90717	94257	96462	36	60	25	-
90718	94258	96463	42	65	25	-
90719	94259	96464	48	70	25	-

NPT thread – female

Part no. light grey RAL 7035	Part no. dark grey RAL 7001	Part no. black RAL 9005	Size NPT	Spanner size mm	Unit	
97317	90870	90875	3/8"	22	100	-
97316	90871	90876	1/2"	27	100	-
97315	90872	90877	3/4"	33	100	-
98366	90873	90878	1"	47	50	-

Dimensions and specifications may be changed without prior notice.