


Synthetic cable glands Syntec® with lamellar technology

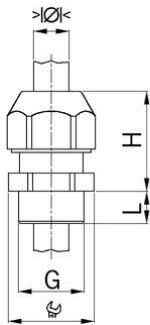

Entry thread NPT

Type approval: SYNTEC

- Black RAL 9005
- One-piece sealing ring

Article no:	1545.N0750.18
E-No:	121758529
EAN:	7611614078427
Material	Polyamide PA 6
Properties	halogen-free, black UV resistant (tested according to EN ISO 4892-2)
Sealing ring	CR (neoprene)
Operation temperature	-30°C / +100°C
Protection class	IP 54
Entry thread	IP 68, if the entry thread is sealed
NEMA Type rating	4X
Entry thread (G)	NPT 3/4"
Clamping range min.	11.0 mm
Clamping range max.	18.0 mm
Wrench size	33 mm
Dimension (H)	35 mm
Thread length (L)	15 mm
UL - clamping range	12.0-18.0 mm
Dispatch	25