 

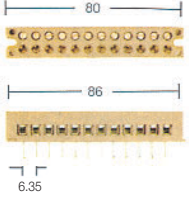
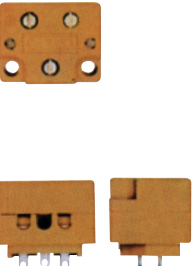

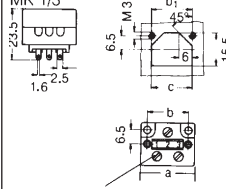
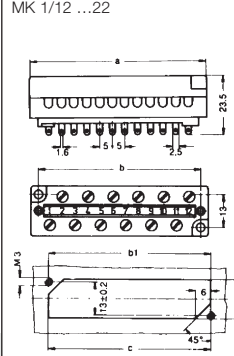

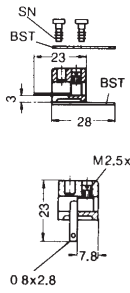




Direct Mount Terminals

Feed Through

	ADK 1		ADK 1 F ADK 3 F		MK 2/12	MK 1/3...22
						
Available Options (thickness mm) For Sheet Metal Version	1.5	2.5	1.5	2.5	Part No.	Part No.
PA	0303860000	0301060000	0476060000	0478660000		
3 pole KrG						0261620000
12 pole KrG						0261820000
12 pole PA					0241460000	
22 pole KrG						0301920000
All types except ADK 1 FT and MK 1/3... internal pin 0.8 x 2.8						
Dimensions						
Width / Length / Height with pins	mm (in.)	6/22/36.5 (.236/.87/1.44)	6/22/36.5 (.236/.87/1.44)	86/15/23 (2.68/.59/.91)	See table below	
Length of solder lug/pin	mm (in.)	8.4 (.33)	8.5/7.5 (.33/.30)	8 (.32)	5 (.20)	
Insulation stripping length	mm (in.)	9 (.35)	11 (.43)	5 (.20)	6 (.24)	
Technical Data						
Rated voltage / rated current / wire size	UL	300 V / 16 A / #22...12 AWG	300 V / 15 A / #26...14 AWG	300 V / 10 A / #24...12 AWG	300 V / 10 A / #24...12 AWG	
	CSA	300 V / 10 A / #26...12 AWG	300 V / 10 A / #22 ...14 AWG	300 V / 10 A / #24...12 AWG	300 V / 10 A / #22...16 AWG	
	VDE	380 VAC / 16 A / 4/1.5 mm ²	380 VAC / 20 A / 2.5/1.5 mm ²	6 VAC / 20 A / 2.5/1.5 mm ²	380 VAC / 20 A / 2.5/1.5 mm ²	
Torque	Nm (lb. in.)	0.5 (5.0)	0.9 (8.0)	0.4 (4.0)	0.4 (4.0)	
Clamping screw	M	3	2.5	2.5	2.5	
End Plate (thickness mm)	Type	Part No.	Type	Part No.	Dimensions	
	PA	AP (3) 0476260000	AP (3)	0476260000	MK 1/3	
	EP		AP (3)	0360000000		
Spacer (thickness mm)						
						
Test Plugs / Sockets						
	PS 2.3	0180400000				
Fuse Pin / Insulating Sleeves / Expansion Rivet					Type Part No.	
	SST 1.3	0306600000	SST 1.3	0306600000		
	IH 2.8	0386060000	IH 2.8	0386060000		
					SN 0200100000	
Marking Tags	Print					
Note: Part numbers shown are for a single card of pre-printed tags numbered 1-50. For additional information, see Accessories section.	Consecutive horizontal	DEK 5/6 0468660001	DEK 5/6	0468660001	BSTb 10/12	0245700000
	Consecutive vertical	DEK 5/6 0468760001	DEK 5/6	0468760001	BSTo 10/12	0245600000
See Accessories section for end brackets, test plugs, additional marking material and accessories.						
					Type Dim. a b b₁ c MK 1/3 25 19 19 19 ±0.2 +0.3 MK 1/12 70 64 64 64.5 MK 1/22 120 114 114 114.5	