

Housing - HC-STA-B24-HHFS-1TTP29-EL-AL - 1412763

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Sleeve housing B24, for single locking latch, Material: Die-cast aluminum, salt water resistant, Cable outlets: 1, straight, Height: 76 mm, Cable gland: none, Gland: no, 1x Pg29, Standard

Why buy this product

- good shielding in the event of electromagnetic interference



Key Commercial Data

Packing unit	1 STK
Custom tariff number	85389099
Country of origin	China

Technical data

Dimensions

Height	76 mm
Width	44 mm
Length	120 mm

Ambient conditions

Degree of protection of housing (IP)	IP66
	IP69K (ISO 20653:2013-02, with suitable screw connection)
	IP67
Degree of protection of housing (NEMA)	4
	4X
	12
Ambient temperature (operation)	-40 °C ... 125 °C

Housing - HC-STA-B24-HHFS-1TTP29-EL-AL - 1412763


Technical data

General

Note	for contact inserts HC-B24, BB46, D64, DD108, HV10/16, M
Size	B24
Housing type	Sleeve housing
Locking type	for single locking latch
No. of cable outlets	1
Cable exit	straight
Screw connection	none
Type of the screw connection	1x Pg29
Housing material	Die-cast aluminum, salt water resistant
Housing surface material	Uncoated

Drawings

Dimensional drawing

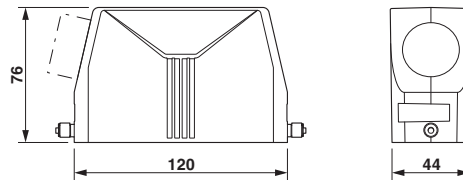

Dimensional drawing

Classifications

eCl@ss

eCl@ss 5.1	27143424
eCl@ss 6.0	27143423
eCl@ss 8.0	27440202
eCl@ss 9.0	27440202

ETIM

ETIM 5.0	EC000437
----------	----------

Approvals

Approvals

Housing - HC-STA-B24-HHFS-1TTP29-EL-AL - 1412763

Approvals

Approvals

EAC / GL

Ex Approvals

Approvals submitted

Approval details

EAC

GL

Accessories

Accessories

Full screw connection

Cable gland - G-INS-PG29-M68N-NNES-S - 1411176



Cable gland, Cable gland material: Brass, nickel-plated, External cable diameter 18 mm ... 25 mm, Shielding: No, Connecting thread: Pg29, Color: silver

Cable gland - G-INSEC-PG29-M68N-NNES-S - 1411201



Cable gland, Cable gland material: Brass, nickel-plated, External cable diameter 18 mm ... 25 mm, Shielding: yes, Connecting thread: Pg29, Color: silver

Labeled device marker

Housing - HC-STA-B24-HHFS-1TTP29-EL-AL - 1412763

Accessories

Plastic label - US-EMLP (20X9) CUS - 0830085



Plastic label, can be ordered: By card, white, labeled according to customer specifications, Mounting type: Adhesive, Lettering field: 20 x 9 mm

Protective cover

Protective covers - HC-B24-HCLWS-PLR-BK - 1414637



HEAVYCON protective cover, B24, for HC-EVO-B24... sleeve housing, with single locking latch, with retaining cord, IP54