


Part Number: TA01XXXX

Type	Size	Rating	Description
LED	8mm	Various	Recessed Bezel LED with flying leads

All dimensions in mm.

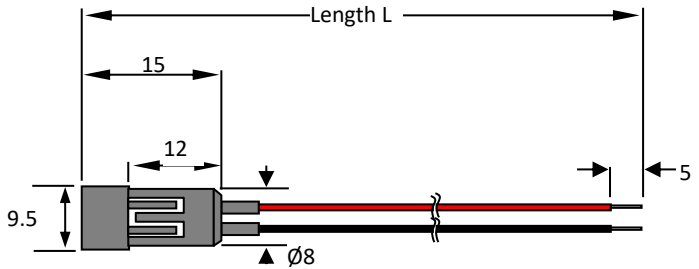

Part no.	Length L	Colour	Volts	Current mA	Intensity mcd	LED
TA010005	500	red	$V_f=2.0$	20	50	standard
TA010009	900	red	$V_f=2.0$	20	50	standard
TA010015	500	green	$V_f=2.0$	20	40	standard
TA010019	900	green	$V_f=2.0$	20	40	standard
TA010025	500	yellow	$V_f=2.1$	20	40	standard
TA010029	900	yellow	$V_f=2.1$	20	40	standard
TA010105	500	red	6DC	16	40	standard
TA010115	500	green	6DC	16	32	standard
TA010125	500	yellow	6DC	16	32	standard
TA010205	500	red	12DC	16	40	standard
TA010209	900	red	12DC	16	40	standard
TA010215	500	green	12DC	16	32	standard
TA010219	900	green	12DC	16	32	standard
TA010225	500	yellow	12DC	16	32	standard
TA010275	500	blue	12DC	16	70	standard
TA010229	900	yellow	12DC	16	32	standard
TA010305	500	red	24DC	10	25	standard
TA010309	900	red	24DC	10	25	standard
TA010315	500	green	24DC	10	20	standard
TA010319	900	green	24DC	10	20	standard
TA010325	500	yellow	24DC	10	20	standard
TA010329	900	yellow	24DC	10	20	standard
TA011005	500	red	3.5-13DC	22@9V	40@9V	flashing
TA011009	900	red	3.5-13DC	22@9V	40@9V	flashing
TA011015	500	green	3.5-13DC	22@9V	40@9V	flashing
TA011019	900	green	3.5-13DC	22@9V	40@9V	flashing
TA011025	500	yellow	3.5-13DC	22@9V	40@9V	flashing
TA011029	900	yellow	3.5-13DC	22@9V	40@9V	flashing
TA011305	500	red	24DC	22	40	flashing
TA011309	900	red	24DC	22	40	flashing
TA011315	500	green	24DC	22	40	flashing
TA011319	900	green	24DC	22	40	flashing
TA011325	500	yellow	24DC	22	40	flashing
TA011329	900	yellow	24DC	22	40	flashing