

# CAB PC 604022 T

**FIBOX**  
Enclosing innovations



Sample image

**Order symbol:** CAB PC 604022 T

**Product nbr:** 8113070

**UL Code:** 8143070

**UL Name:** UL CAB PC 604022 T

**Description:** Smoked transparent door


**Remarks:** Latches on the long side

**Including:** Cabinet base, door with PUR gasket, latches, screws for mounting plate/DIN-rail and corner plugs.

**EAN:** 64 1807402045 1

**El. number:**

- Finland: 3424176
- Denmark: 8212020294
- Sweden: 2539957

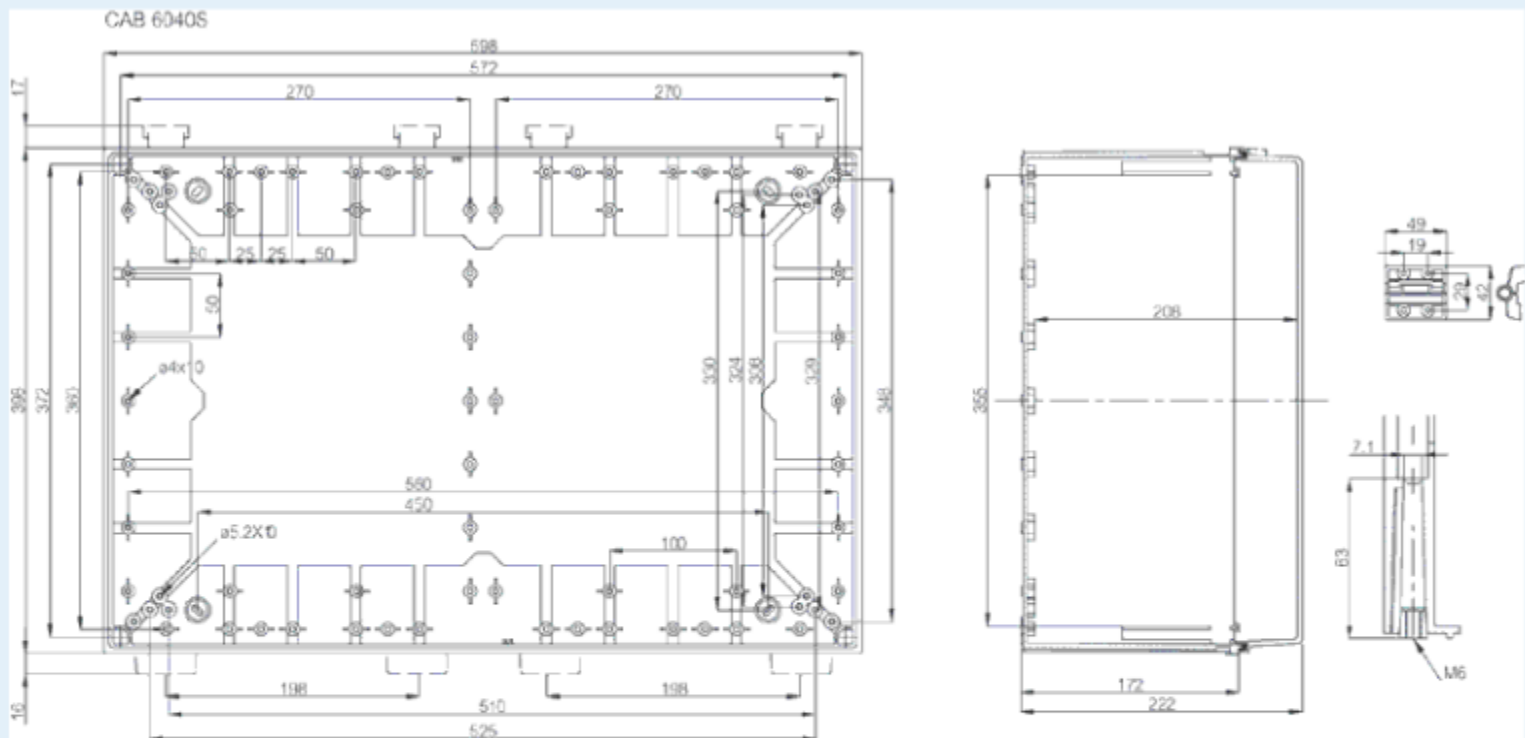

Dimensions:	Height	Width	Depth
mm:	600	400	220
inch:	23.62	15.75	8.66

#### Materials:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	Clear transparent
Gasket material:	Polyurethane

#### Temperatures:

Temperature °C (short term):	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

#### Rating:

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

#### Certificates:

Certificate FI 40854