

# ARCA 403015 No MP



Sample image

**Order symbol:** ARCA 403015 No MP

**EAN:** 6418074089342

**Product nbr:** 8120006N


**El. number:**

**Description:** Cabinet. PC

- Finland:
- Denmark:
- Sweden:

**Remarks:** Grey cover. 2-point locking. hinges on the long side

**Including:** Cabinet base. door with PUR gasket. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

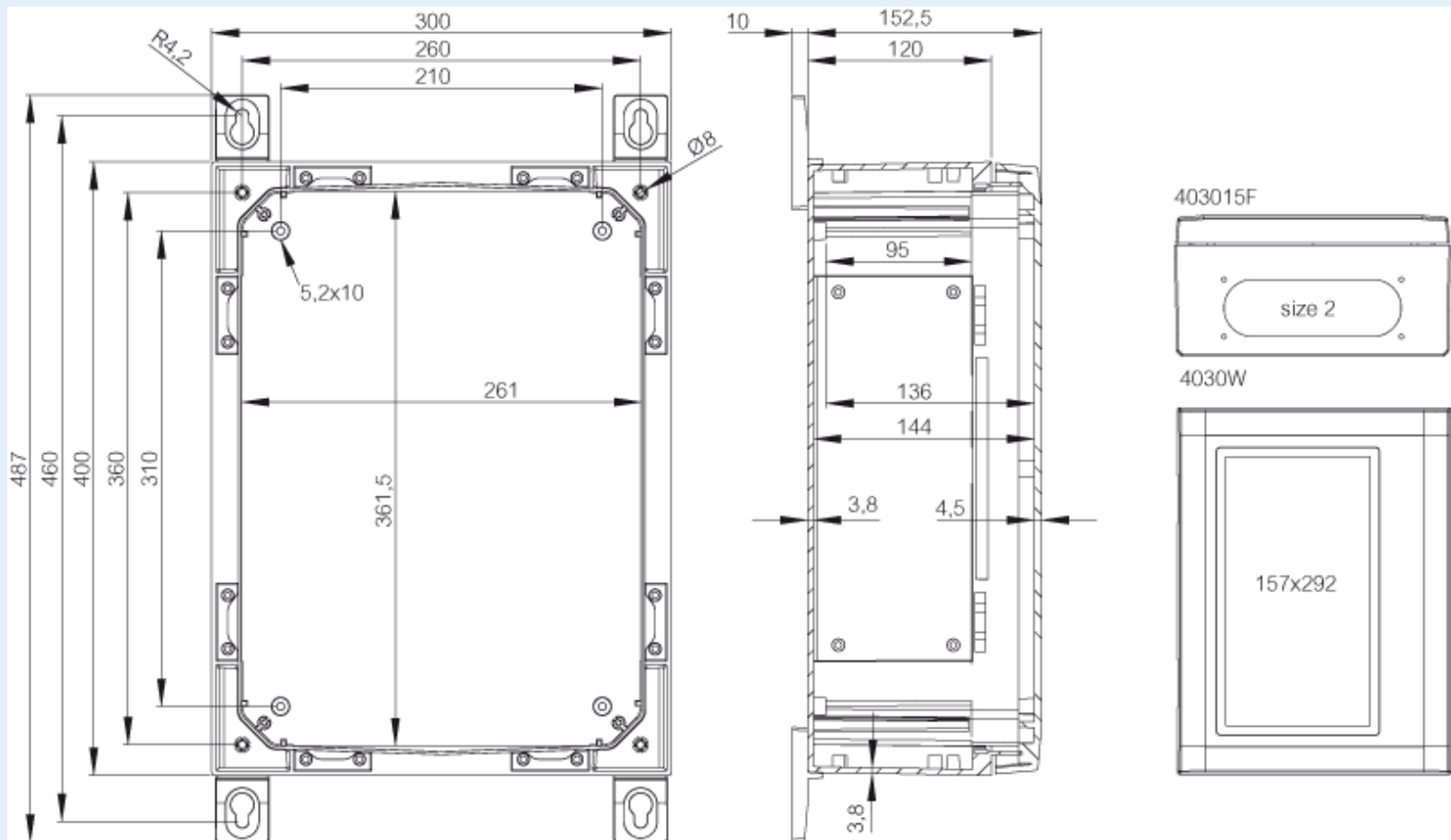

<b>Dimensions:</b>	<b>Height</b>	<b>Width</b>	<b>Depth</b>
mm:	400	300	150
inch:	15.75	11.81	6.22

#### **Materials:**

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

#### **Temperatures:**

Temperature °C (short term)::	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

#### **Accessories:**

DRS ARCA 403015	DIN rail frame set (385 x 285 x 35)
SBK ARCA 30	Support bar kit (235 x 40 x 30)
RCS ARCA 4030	Rain canopy set for size 4030 (20 x 300 x 30)
SBK ARCA 40	Support bar kit (340 x 40 x 30)
IDS ARCA 4030	Inner door set (385 x 285 x 35)
PMK ARCA 30	PoleMounting kit. for pole ø100-300mm (385 x 285 x 35)
DSP ARCA VLS	Door stopper ARCA. vertical. left. small
MPMP ARCA 4030	Mounting plate multiperforated (350x250x2 mm - ø3.6 mm) (350 x 250 x 2)
DSP ARCA VRS	Door stopper ARCA. vertical. right. small
MPS ARCA 4030	Mounting plate (350x250x2 mm) (350 x 250 x 2)
MPP ARCA 4030	Mounting plate perforated (350x250x2 mm - 26x11 mm) (350 x 250 x 2)
MPX ARCA 4030	Mounting plate (350x250 mm) (350 x 250 x 5)

#### **Rating:**

Ingress protection (EN 60529):	IP66;
Impact Resistance (EN 62262):	IK10;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 94 5VA
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	NEMA 1, 4, 4X, 12 and 13

#### **Certificates:**

Certificate FI 40467