


# RB1881 Series

182 x 171 x 82mm (7.2 x 6.7 x 3.2 in)

- 24V, 48V
- Ball bearings
- 137 CFM
- Frame and Impeller: Aluminum
- Lead Wires: UL (+) Red; (-) Black
- Operating temperature: -10°C ~ +70°C
- Operating life: 50,000 hours
- UL, cUL, CE Listed
- RoHS Compliant



| Model Number | V  | Range (V) | A   | RPM  | CFM   | m <sup>3</sup> /min | mmAq | inH <sub>2</sub> O | dBA |
|--------------|----|-----------|-----|------|-------|---------------------|------|--------------------|-----|
| RBH1881B2    | 24 | 12.0~27.6 | 2.2 | 2000 | 136.8 | 3.87                | 63.8 | 2.51               | 63  |
| RBH1881B4    | 48 | 24.0~55.2 | 1.1 | 2000 | 136.8 | 3.87                | 63.8 | 2.51               | 63  |

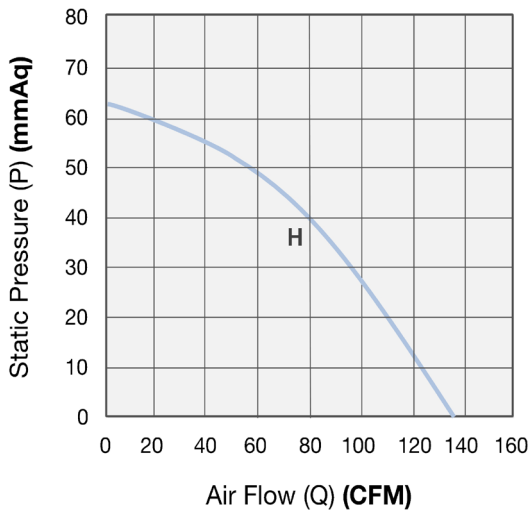

- Optional Features
- Inrush Current Protection
  - Autostart
  - Tachometer
  - Rotation Detector
  - Life Detection
  - Over Voltage Protection
  - VPWM
  - IPWM
  - PPWM
  - TPWM
  - RPWM
  - Current Limit Control
  - Constant Speed
  - IP56
  - IP67