

# PC 95/35 LT



Sample image

**Order symbol:** PC 95/35 LT

**Product nbr:** 6012931

UL Code: 6412931

UL Name: UL PC 95/35 LT

**Description:** Enclosure. PC

**Remarks:** Smoked transparent cover


**Including:** Base with PUR gasket. screws for mounting plate/DIN-rail and cover with polyamide cover screws.

**EAN:** 6418074054654

**El. number:**

- Finland: 3421368
- Denmark: 8212027695
- Sweden: 6012931

# MNX 100×100×35-50

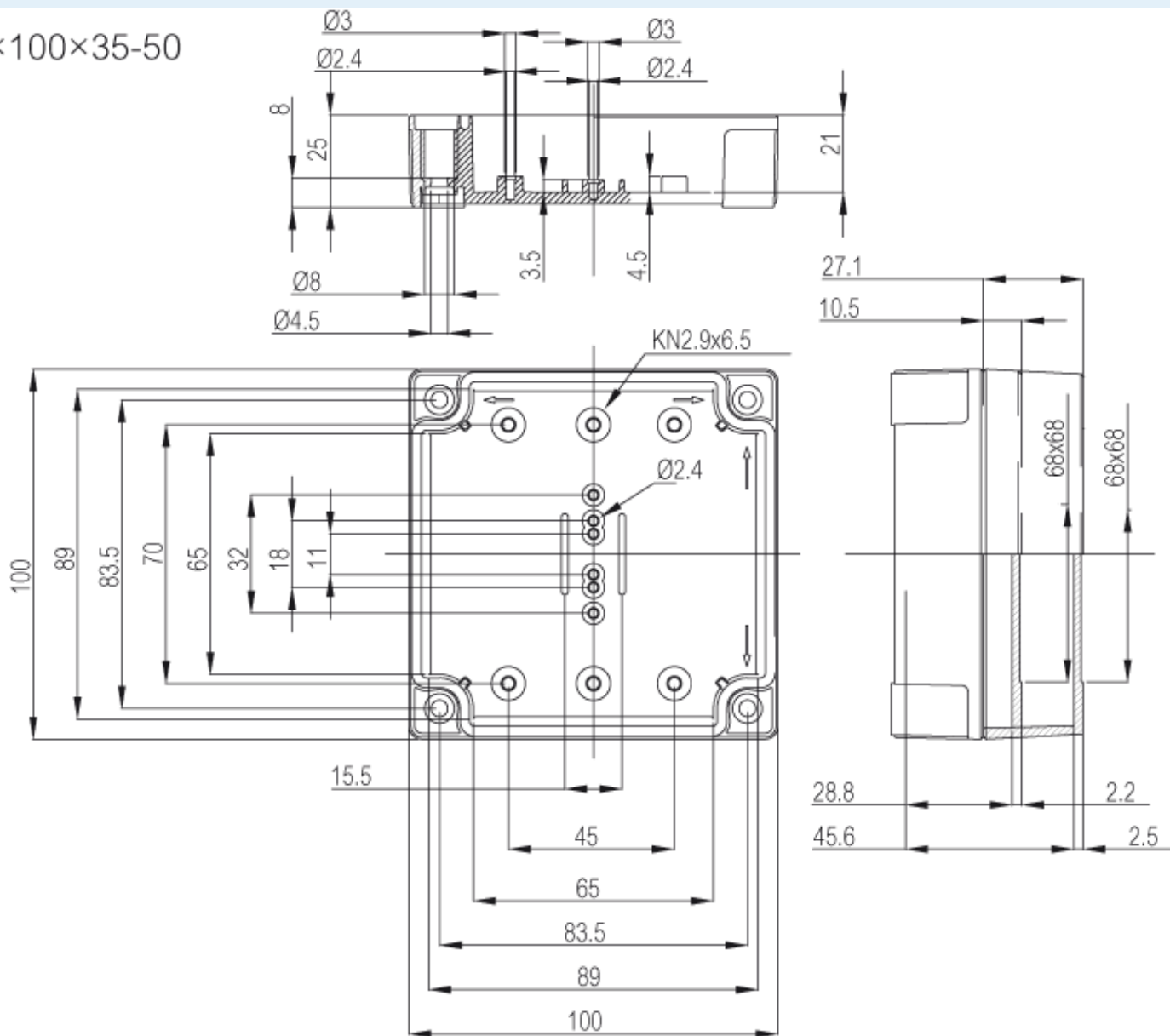

## Dimensions:

	Height	Width	Depth
mm:	100	100	35
inch:			

## Materials:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	Clear transparent
Gasket material:	Polyurethane

## Temperatures:

Temperature °C (short term)::	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

## Accessories:

MIN 8	DIN-15 Mounting rail. for enclosures: (80 x 15 x 1)
B-3	DIN-35 Mounting rail. for enclosures: (80 x 35 x 1)
FP 22046	Mounting foot kit (4 pcs)
MIV 95	Back Panel (Galvanized steel). for enclosures: (66 x 80 x 1)

## Rating:

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

**Certificates:**

Certificate FI 40847