

LED EA19-11W2020eG-2

Bulb Class: A19

Product Description

LED EA19-11W2020eG-2, Omni-directional A19, replaces conventional 75 Watt incandescent bulbs delivering more brightness (lumens) for less energy (Watts). With lower energy consumption levels you will be able to experience considerable energy savings throughout the years. EA19-11W2020eG-2 design reduces internal bulb heat providing greater durability and constant bulb performance. Look for EA19-11W2000eG-2 for Soft White (3000K), EA19-11W2040eG-2 for Bright White (4000K) and EA19-11W2050eG-2 for Cool White (5000K). Enjoy features such as: Instant-on, dimming options, Energy Efficient, and Enclosed Fixture Suitable.



Estimated Energy Cost: \$1.32 per year

*Note: Design, features and specifications subject to change without notice. Some features may not be available on all models. Please visit www.eurilighting.com or call 1-310-787-1100 for more information.

Specifications

Input Power	Input Voltage	Lumen Output	Beam Angle	Center Beam	CCT
11 W	120 V	1100 lm	220°	N/A	2700 K
CRI	Luminous Efficacy	Power Factor	Input Current	Base	Lamp Lifespan
80	100 lm/W	0.7	0.13 A	GU24	25,000 Hrs.

Product Features



Dimmable



Enclosed Fixture Suitable




Energy Efficient



Damp Rated

Product Dimensions

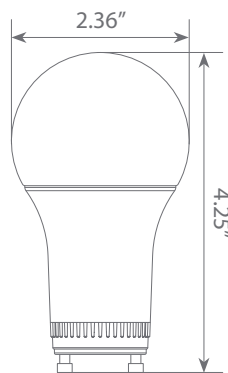

Product Photometric Data

