




Our Planetary Gear Motors are an inline solution providing excellent torque output at various speeds. They are equipped to handle varying loads and are best for intermittent duty operation. With endless performance combinations, we have a fully tailored gear motor solution for you.



Contact Us for alternative solutions!

Specifications			
Gearhead Type:	Planetary	No-Load Speed:	87 rpm (+/- 10%)
Motor Type:	Carbon - Brushed	No-Load Current:	< 60 mA
Rated Voltage:	24V DC	Stall Torque:	8.25 kg.cm
Rated Speed:	71 rpm	Max. Power:	1.95 W
Rated Torque:	1.40 kg.cm	Reduction Ratio:	104:1
Rated Current:	140 mA	Termination Style:	Terminals

Dimensions

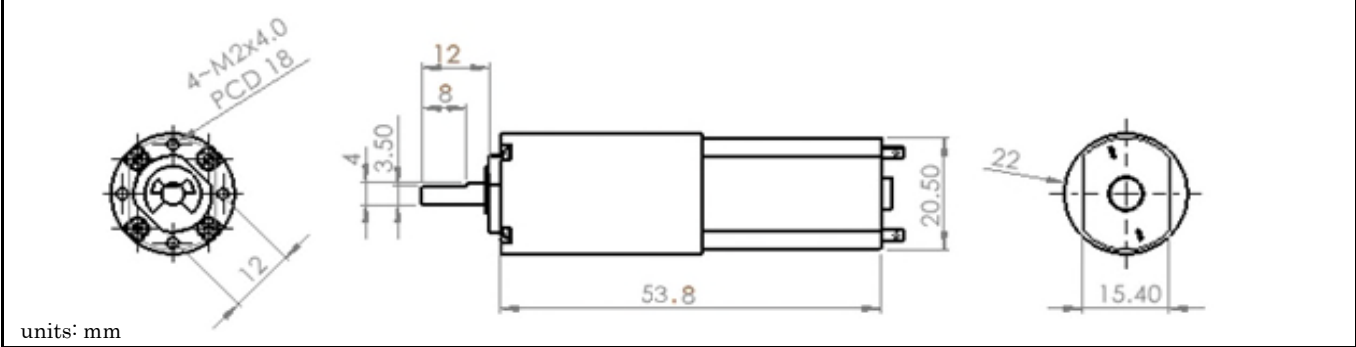

Performance Curve

