


Mercury-15W

15.6 Inch Wide Screen System


OUTDOOR COMPUTER

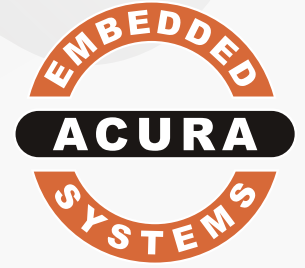

IP65
FRONT AND BACK



-30°C TO +60°C

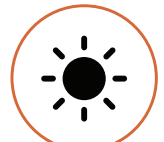

SUNLIGHT READABLE



WIRELESS CONNECTIVITY



LIGHTWEIGHT




CUSTOM BUILD



Mercury-15W

15.6 Inch Wide Screen System

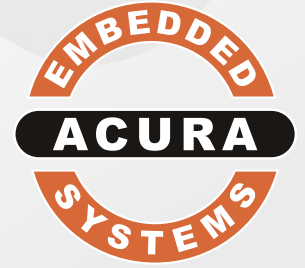

OUTDOOR COMPUTER

FULLY CUSTOMIZABLE | 3 YEAR WARRANTY

SYSTEM

SCREEN SIZE	15.6" WIDE SCREEN LCD
PROCESSOR	INTEL J1900, i5 OR i7 CPU
BRIGHTNESS	1000 NITS - HIGH BRIGHT
MEMORY	1x DDR4 - MAX 32 GB
LCD TYPE	LED BACKLIT
TOUCH SCREEN	CAPACITIVE MULTI TOUCH
POWER INPUT	9 - 36V DC POWER INPUT
OPERATING SYSTEM	WINDOWS 7/10 OR LINUX
STORAGE	SATA TYPE III - HDD/SSD

I / O

LAN	2x RJ45 GBE PORT (MODIFIABLE)
USB	3x USB (MODIFIABLE)
WIFI	802.11 A/B/G/N
WIRELESS AUXILIARY	4G/LTE (SIM CARD SLOT) 2x PORTS (MODIFIABLE)

ENVIRONMENTAL

OPERATING TEMP	-30°C TO +60°C (-22°F TO 140°F)
STORAGE TEMP	-40°C TO +70°C (-40°F TO 158°F)
RELATIVE HUMIDITY	<96% (NON CONDENSING)
IP RATING	IP65 FRONT AND BACK WASHABLE
NEMA RATING	NEMA4 CORROSION RESISTANT

MECHANICAL

MOUNTING	CHAIN, PANEL AND WALL VESA MOUNT 100 x 100 mm
WEIGHT	5.5 KG - 12.1 LBS
DIMENSIONS	16.3" x 10.4" x 2.3" 41.6 x 26.4 x 5.8 cm

MODEL NUMBERS

J1900 CPU	MDL# AP15WJ1900
INTEL i5 CPU	MDL# AP15Wi5
INTEL i7 CPU	MDL# AP15Wi7

ACURA EMBEDDED SYSTEMS INC.

#101 - 17825 64 AVE, SURREY BC
V3S 1Z3 CANADA
WWW.ACURAEMBEDDED.COM

PHONE NUMBER: +1 (604) 502-9666 | TOLL-FREE: 1-866-502-9666
EMAIL: CONTACT@ACURAEMBEDDED.COM

