



Our Planetary Gear Motors are an inline solution providing excellent torque output at various speeds. They are equipped to handle varying loads and are best for intermittent duty operation. With endless performance combinations, we have a fully tailored gear motor solution for you.




[View Alternative Solutions!](#)

Specifications

Gearhead Type:	Planetary	No-Load Speed:	211 rpm (+/- 10%)
Motor Type:	Carbon - Brushed	No-Load Current:	< 310 mA
Rated Voltage:	24V DC	Stall Torque:	* 22.25 kg.cm
Rated Speed:	161 rpm	Max. Power:	12 W
Rated Torque:	5.3 kg.cm	Reduction Ratio:	35:1
Rated Current:	1 A	Termination Style:	Terminals

* Gearbox limitations are set at 18 kg.cm, operating past this torque limit may create premature failure.

Dimensions

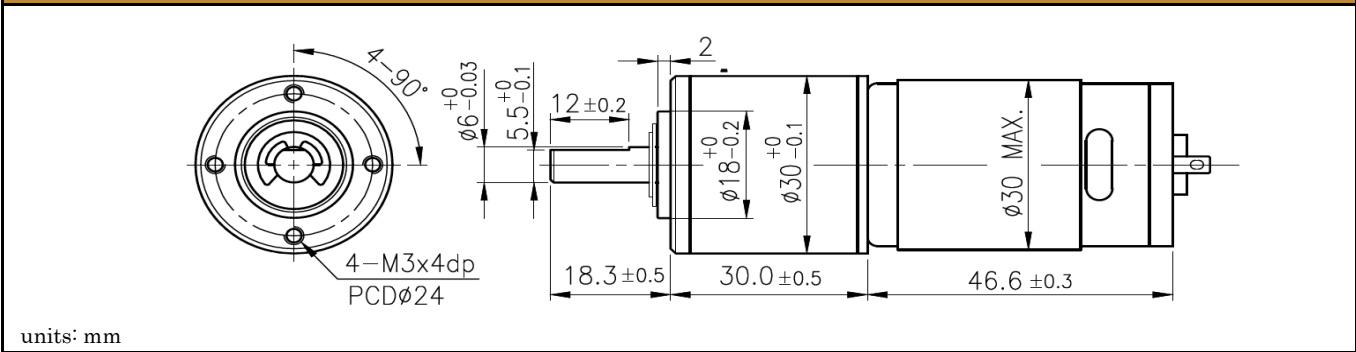

Performance Curve

