

Specifications Sheet

Product Type : ***Mechanical Buzzer***

Product Series : ***BS2416L-24-B***

Description : ***MC BUZZER SINGLE 24VDC L/W ABS RoHS***

Color : ***Black***


Electrical Specifications

Model No.	BS2416L-24-B	
Operating Voltage Range (VDC)	15.0 ~ 27.0	
Rated Voltage (VDC)	24.0	
* Max. Rated Current (mA)	30.0	
* Min. Sound Output (dBA/ 20.0 cm)	75.0	
* Frequency (Hz)	400.0 ± 100.0	
Tone Nature	Single	
Operating Temperature (° C)	- 20.0 ~ + 60.0	
Storage Temperature (° C)	- 30.0 ~ + 70.0	
Terminal	Leadwire (UL1095 , AWG#26)	
Housing Material	ABS	
Weight (g)	10.0	

* Value applying at rated voltage

Dimensions

Unit : mm Tolerance : ± 0.5 mm

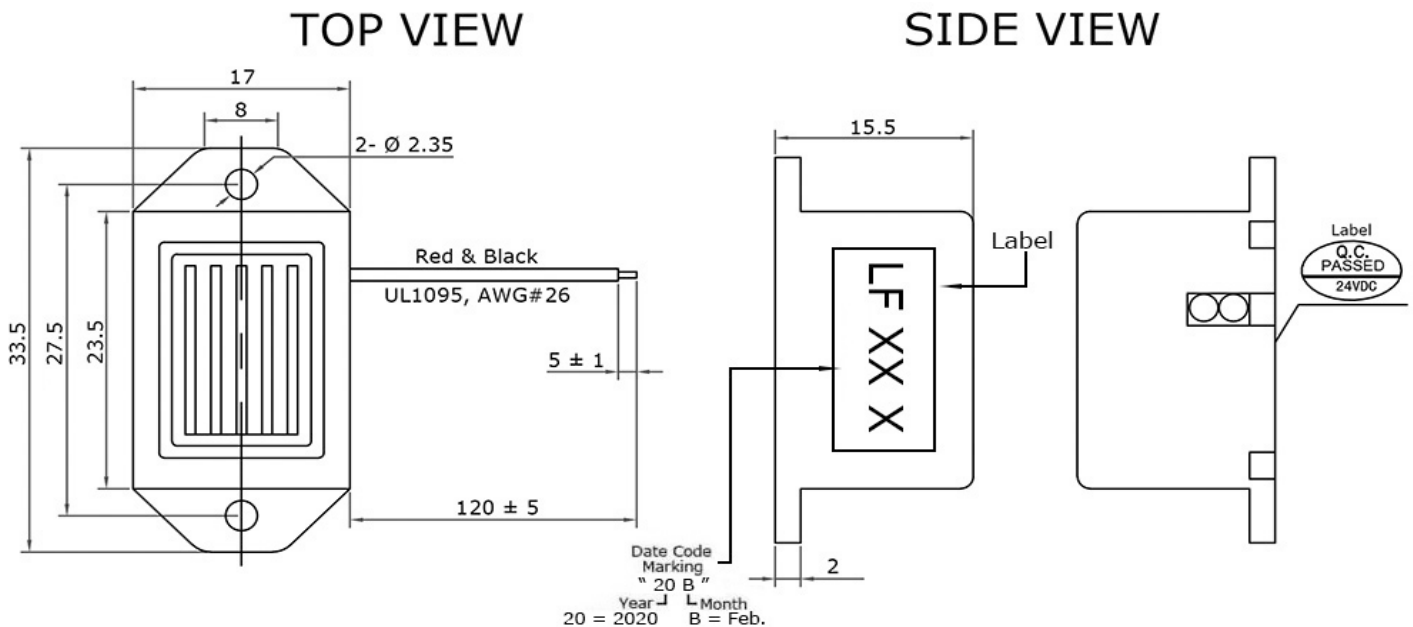

Approved By : JL
Date : 10 Feb 2020

Prepared By : LL
Date : 10 Feb 2020

Modify :	Date :	By :
Ref. : 3-001		