


HDC 06B TOS 1M25 WMP**Weidmüller Interface GmbH & Co. KG**Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

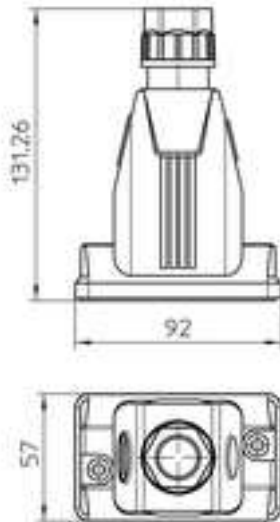

Our flange-mounted housings made of plastic have a built-in cable gland and a screw interlock. They seal directly onto the panel wall and can therefore be used without an attachment housing. The housings are impressive with their low weight and optimal protection against contamination, water and vibrations.

General ordering data

| | |
|------------|---|
| Version | HDC enclosures, Size: 3, Protection degree: IP66 (in plugged condition), IP67 plugged, Cable entry from top, Screw, , Size of cable entries: M 25 |
| Order No. | 2716700000 |
| Type | HDC 06B TOS 1M25 WMP |
| GTIN (EAN) | 4050118806663 |
| Qty. | 1 pc(s). |

HDC 06B TOS 1M25 WMP

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Dimensions and weights

| | |
|------------|-------|
| Net weight | 122 g |
|------------|-------|

Cable Gland WMP

| | | | |
|----------------------|-------|-----------------------|-------|
| Cable diameter, min. | 9 mm | Cable diameter, max. | 17 mm |
| AF size | 26 mm | Size of cable entries | M 25 |

Dimensions

| | |
|-------------|-----------------|
| Cable entry | w. cable glands |
|-------------|-----------------|

General data

| | | | |
|-----------------------------|-----------------------------|---------------------------|---|
| EMC housings | No | Housing main material | PA |
| Material of locking element | Stainless steel, rust-proof | Protection degree | IP66 (in plugged condition), IP67 plugged |
| Tightening torque | 3 Nm | UL 94 flammability rating | V-0 |

Version

| | | | |
|--------------------------|------------|------------------------------|----------------------|
| BG | 3 | Cable entry | w. cable glands |
| Colour (RAL) | RAL 9011 | Design of housing | Cable entry from top |
| Design of locking system | Screw | Number of cable entry on top | 1 |
| Number of cable glands | 1 | Sealing | NBR |
| Size | 3 | Size of cable entries | M 25 |
| Suitable for ModuPlug® | Yes | Tightening torque | 3 Nm |
| Top part/bottom part/lid | upper part | | |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC000437 | ETIM 7.0 | EC000437 |
| ETIM 8.0 | EC000437 | ECLASS 9.0 | 27-44-02-02 |
| ECLASS 9.1 | 27-44-02-02 | ECLASS 10.0 | 27-44-02-02 |
| ECLASS 11.0 | 27-44-02-02 | ECLASS 12.0 | 27-44-02-02 |

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Downloads

| | |
|---|--|
| Approval/Certificate/Document of Conformity | Manufacturer's declaration |
| Engineering Data | CAD data – STEP |
| Catalogues | Catalogues in PDF-format |

HDC 06B TOS 1M25 WMP

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

Drawings

www.weidmueller.com

