

LED EA21-22W1040eh

Bulb Class: A21



Product Description

LED EA21-22W1040eh replaces conventional 150 Watt incandescent bulbs delivering more brightness (lumens) for less energy (Watts). With lower energy consumption levels you will be able to experience considerable energy savings throughout the years. **EA21-22W1040eh** design reduces internal bulb heat providing greater durability and constant bulb performance.



Estimated Energy Cost: \$2.64 per year

*Note: Design, features and specifications subject to change without notice. Some features may not be available on all models. Please visit www.eurilighting.com or call 1-310-787-1100 for more information.


Specifications

Input Power	Input Voltage	Lumen Output	Beam Angle	Center Beam	CCT
22 W	120V	2550 lm	210°	N/A	4000 K
CRI	Luminous Efficacy	Power Factor	Input Current	Base	Lamp Lifespan
80	115.9 lm/W	0.7	0.2 A	E26	25,000 Hrs.

Product Features

- Dimmable
- Enclosed Fixture Suitable
- Energy Efficient
- Damp Rated
- High Output

Product Dimensions

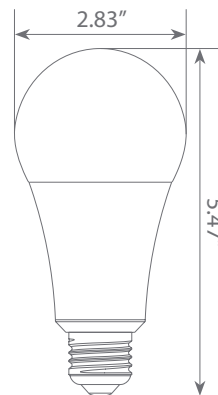

Product Photometric Data

