



touch screen



HDMI

VGA

IP66
OUTDOOR RATEDIP69K
SANITIZATION
WASH DOWN

IP69K WATERPROOF
SUNLIGHT READABLE

24" MONITOR




XENARC
TECHNOLOGIES



- IP69K rated for high pressure high temperature spray downs
- IP66/NEMA4X Waterproof and Dust Proof
- Stainless Steel Enclosure suitable for spray downs
- Projected Capacitive Touchscreen option – USB
- 1920 x 1080 Wide Viewing Angle IPS Panel
- VGA and HDMI Inputs
- 16x9 Aspect Ratio
- LED Backlight, Ambient Light Sensor
- High Performance Image and Video Signal Processor
- VESA 100mm and 200mm x 100mm Standard
- Brightness – 1000 cd/m² Sunlight Readable
- -30°C ~ 70°C Wide Operating Temperature Range

Physical Resolution : 1920 x 1080
Supported Resolution : 640 x 480 ~ 1920 x 1080
Brightness : 1000 cd/m²
Contrast Ratio : 5000 : 1
Viewing Angle : 178° Horizontal, 178° Vertical
Response Time (Tr+Tf) : 25 ms (Typ.)
Operating Voltage: DC 9V ~ 36V
Power Consumption: <45W
Operating Temp: -22°F ~ 158°F
Storage Temp: -22°F ~ 167°F
Humidity: 5%~95% RH (Non-Condensing)
Weight: 24.9lbs (2409YNH) / 22.65lbs (2409CNH)
36 Month Warranty
All measurements are in [mm]

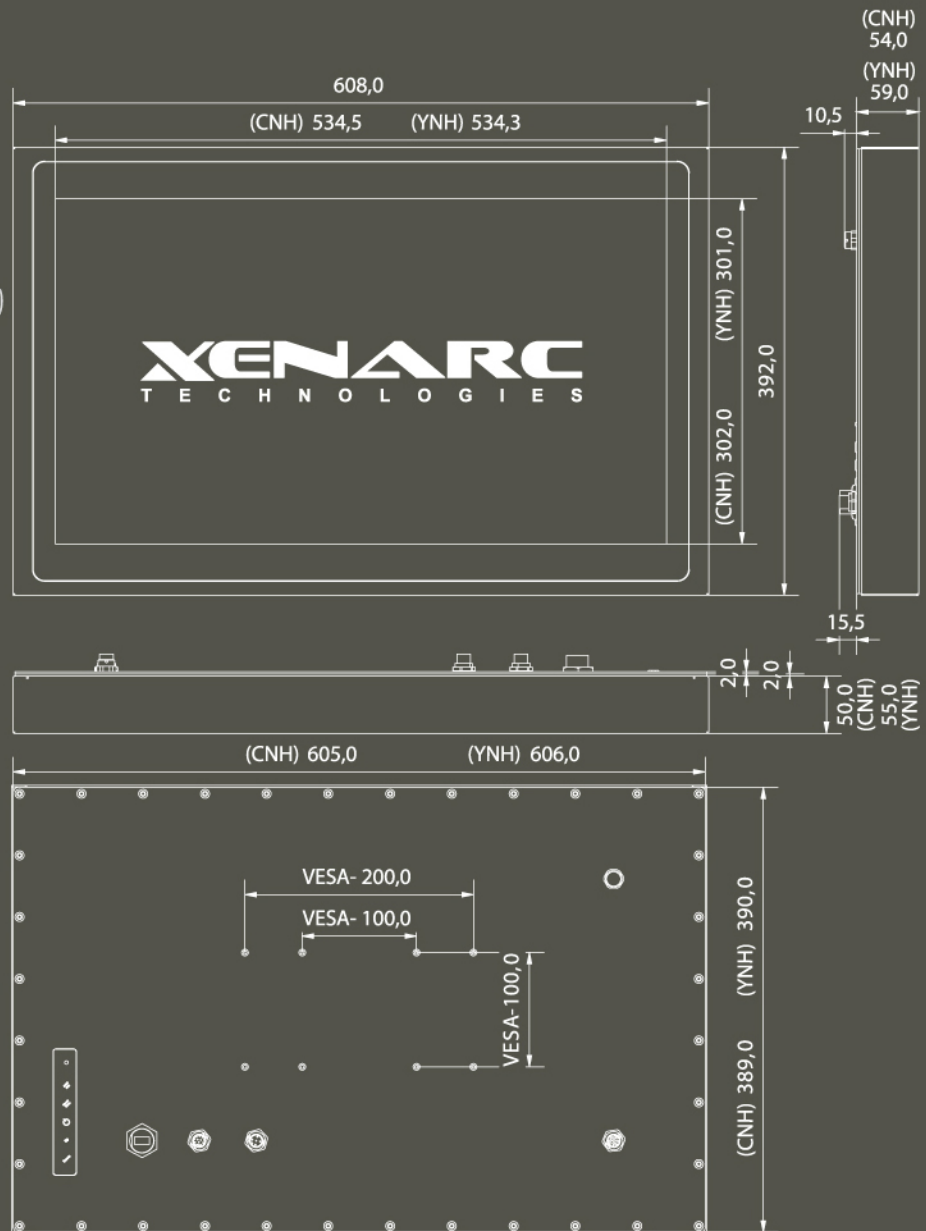

IP69K WATERPROOF
SUNLIGHT READABLE
24" MONITOR

CERTIFICATIONS



TEL: 949.380.8898 FAX: 949.380.0888
EMAIL: SALES@XENARC.COM