

# Neodymium shallow pot datasheet

## -Internal thread


- Zinc plated body
- With threaded stem
- 80° max operating temp



### Product Information

#### Neodymium shallow pot with internal thread

Product No.	Diameter <i>mm</i> <i>D</i>	Overall Height <i>mm</i> <i>H</i>	Thread	Weight <i>g</i>	Pull force <i>Newtons</i>
E1018/NEO	10	4.5	M3	2.5	10
E1019/NEO	13	4.5	M3	4.3	25
E1020/NEO	16	4.5	M4	6.3	50
E1021/NEO	20	6	M4	11	70
E1022/NEO	25	7	M5	21	135
E1023/NEO	32	7	M6	36	250
E1024/NEO	40	8	M6	68	390
E1025/NEO	48	11.5	M8	139	570

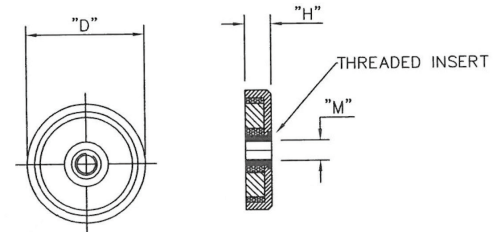

If you have any more questions, require technical assistance and would like a quotation, simply contact us.

[www.eclipsemagnetics.com](http://www.eclipsemagnetics.com)

Eclipse Magnetics Ltd, Atlas Way, Sheffield, S4 7QQ, England  
 T +44 (0)114 225 0600 F +44 (0)114 225 0525 E [info@eclipsemagnetics.com](mailto:info@eclipsemagnetics.com)

While every effort has been made to ensure the accuracy of the information in this publication please note that specifications may change without notice.



FM31278