


CSB-M1251M1251

► SPLITTERS

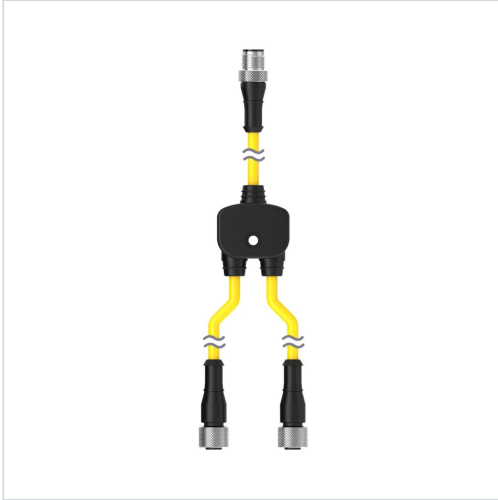

Euro-style Quick Disconnect Splitter Cable

5-Pin Straight male Eurofast 0.30 m (1 ft) Trunk

5-Pin Straight Female Eurofast 0.30m (1 ft) Branch 1

5-Pin Straight Female Eurofast 0.30 m (1 ft) Branch 2

Nickel Plated Brass Coupling Nuts Yellow Jacket

Part Number: 93317

SPECIFICATIONS

Number of Contacts	5
Number of Connectors	3
Cable Jacket Material	PVC
Cable Jacket Color	Black
Connector Body Material/Color	PUR Black
Outside Cable Diameter (mm)	5.5
Cordset Length (m)	0.6
Trunk Length (m)	0.3
Shield/No Shield	No Shield
Coupling Material/Color	Nickel Plated Brass
Maximum Temp. (°C)	105
Current Rating (A)	4.0

Minimum Temp. (°C)	-40
Voltage Rating (V)	250 V ac/300 V dc
IP Rating	IP67
Primary Connector Type	EURO
Primary Coupling Method	M12 Single Key
Primary Gender	Male
Primary Orientation	Straight
Primary Number of Conductors	5
Primary AWG	22
Splitter Cable Diameter	5.5, 5.5
Splitter Branches: Connector Type	M12F, M12F
Splitter Branches: Coupling Method	M12 Single Key, M12 Single Key
Splitter Branches: Orientation	Straight, Straight
Splitter Branches: Number of Conductors	5, 5
Splitter Branches: AWG	22, 22
Splitter Branches Length (m)	0.3, 0.3
Splitter Function	Parallel
Feature: Hazardous Area	No
Oil/Grease Resistant	No



Banner Engineering Corp. | 9714 Tenth Avenue North | Minneapolis, MN 55441 | United States of America

 Chat with an Expert

