 


SPECIFICATIONS:

Insulation Resistance: 1,000MΩ min. at 500V DC
 Withstanding Voltage: 500Vrms for 1min
 Voltage Rating: 5Vrms DC
 Current Rating: 0.5A
 Contact Resistance: 100mΩ max. at 20mV max.
 Operating Temp.: - 25°C ~ +85°C
 Mating Cycle: 5,000 times

PART NUMBER:


PJS008-4100-0-VE



MATERIALS AND FINISH:

- Contacts: Ni-Au Alloy
- Metal Shell: Ni-Au Alloy
- Insulator: LCP

AUTOMOTIVE COMPLIANT

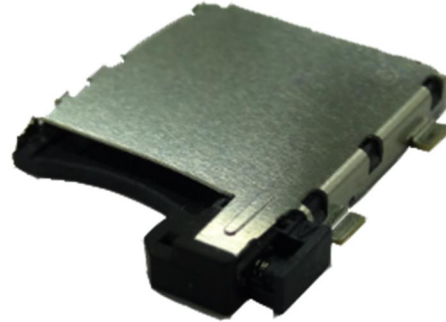

FEATURES:

- Automotive Grade Performance
- High impact and vibration resistance
- One-action Push-Lock latch prevents SIM card ejection during vehicular operation
- RoHS and REACH Compliant

OUTLINE DIMENSIONS:

