



75W
REPLACEMENT

LED EP30-11W5000cecs-2

3000K
CCT

Bulb Class: PAR30 (Short Neck)

90+
CRI
True COLOR

JA8
COMPLIANT

Product Description

LED EP30-11W5000cecs-2 delivers superior brightness, valuable energy savings, long lasting performance and true color perception. These short neck PAR30 LED spot bulbs are ideal for task lighting due to its uniform *Soft white light (3000K) and replace conventional 75 Watt incandescent light bulbs. Enjoy features such as: Instant on, dimming options, energy efficient, 90+CRI, and damp rated.



Estimated Energy Cost: \$1.32 per year

*Note: Design, features and specifications subject to change without notice. Some features may not be available on all models. For more information regarding dimmer compatibility please visit: www.eurilighting.com or call 1-310-787-1100

Available only as a twin-pack.
(EP30-11W5000cecs-2 contains 2 LED Bulbs.)


Specifications

Input Power	Input Voltage	Lumen Output	Beam Angle	Center Beam	CCT
11 W	120V/60Hz	975 lm	40°	N/A	3000 K
CRI	Luminous Efficacy	Power Factor	Input Current	Base/Cap	Lamp Lifespan
90	88 lm/W	0.7	0.1 A	E26	25,000 Hrs.


Product Features

- Dimmable
- Energy Efficient
- Wet Rated

Product Dimensions

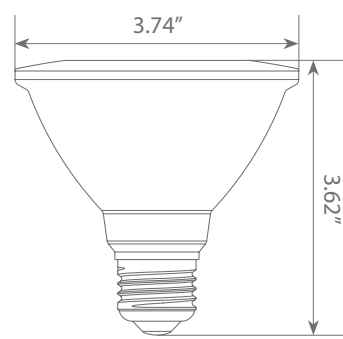

Product Photometric Data

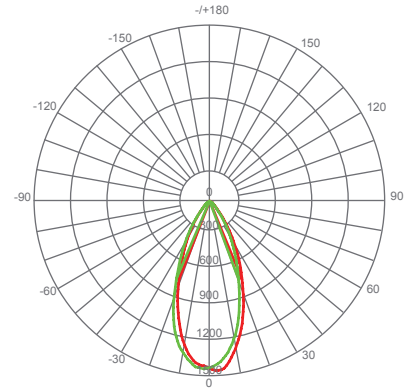

Euri Lighting | A Division of IRTRONIX Inc.

20900 Normandie Avenue Bldg. B, Torrance, CA 90502 | Tel: 310.787.1100 | Fax: 310.787.1166 | www.eurilighting.com

©2020 Euri Lighting. All Rights Reserved