

# T300RGBW-24V-KIT

## 5.8W RGBW LED Tape Light Kit, High Output

### SPECIFICATION FOR TAPE:

<b>Input Voltage</b>	24VDC
<b>Wattage</b>	5.8 W/ft
<b>Output</b>	RGB30K
	RGBW 289 lm/ft
	Red (620-625nm) 22 lm/ft
	Green (520-525nm) 62 lm/ft
	Blue (465-470nm) 14 lm/ft
3000K	180 lm/ft
<b>IP Rating</b>	IP20
<b>CRI</b>	90+
<b>Dimmable</b>	0-10V, ELV, MLV
<b>Max. Run Length</b>	16 ft
<b>Field Cuttable</b>	4" cut points
<b>Beam Angle</b>	120°
<b>LED Tape Operating Temp.</b>	-13 °F to 140 °F
<b>LED Tape Warranty</b>	3 year limited*
<b>LED Tape Adhesive</b>	3M™ VHB mounting adhesive on
<b>LED Tape Dimensions</b>	0.47" W x 0.08" H (12.0mm x 2.0mm)
<b>Lifetime</b>	50,000 Hours
<b>Warranty</b>	5 year limited
<b>Incl. Power Supply</b>	120 VAC to 24VDC, 96W



**HIGH QUALITY  
LED LIGHTING KITS**



### Applications:

- Indoor signage
- Indirect lighting
- Accent lighting
- Undercabinet

### INCLUDED IN KIT




**T300RGB-XXV-KIT  
16FT TAPELIGHT REEL**

1 OF EACH



**PW9624V  
24V POWER SUPPLY**

1 OF EACH

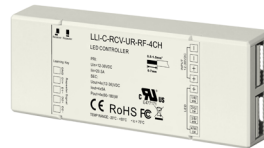

**RGB/W RECIEVER**

1 OF EACH



**RGB/W REMOTE**

1 OF EACH



**GRIPPER-TT-RGBW  
GRIPPER-TW-RGBW**

2 OF EACH

T300RGBW-24V-KIT

## 5.8W RGBW LED Tape Light Kit, High Output

INCLUDED IN KIT



RGB-TOUCH-WM-HW  
WALL MOUNTED TOUCH CONTROLLED  
1 OF EACH

### WIRING DIAGRAM

