

# LED ETF24-50W103sw-2



Class: 2ft. x 4ft. Recessed

## Product Description

LED ETF24-50W103sw-2 is a color temperature and wattage selectable replacement to traditional fluorescent troffers, featuring an ultra slim design, and three wattage options, 33W/40W/50W on each unit, for a lumen output of either 4125lm/5000lm/6250lm. This troffer provides 50,000 hours of life with consistent light output, and offers three color temperature options: Soft White (3000K), Bright White (4000K), and Cool White (5000K). Its best suitable for commercial locations where quality lighting is needed including: office buildings, retail spaces, schools, and health care facilities. This troffer also features 0-10V dimming, 80 CRI, operates on a 120-277V line, and is available in a 2-pack.



**Estimated Energy Cost: \$3.97 per year**

\*Note: Design, features and specifications subject to change without notice. Some features may not be available on all models. Please visit [www.eurilighting.com](http://www.eurilighting.com) or call 1-888-743-5766 for more information.



Available only as a twin-pack.  
Contains 2 troffers.


## Specifications

Input Power	Input Voltage	Lumen Output	Beam Angle	Center Beam	CCT
33 / 40 / 50 W	AC120 - 277V	4125 / 5000 / 6250 lm	120°	N/A	3000 / 4000 / 5000 K
CRI	Luminous Efficacy	Power Factor	Input Current	Base	Lamp Lifespan
80	125 lm/W	0.9	0.45 A	N/A	50,000 Hrs.

### Product Features

- 0-10V Dimmable
- Energy Efficient
- 3 CCT Selectable
- Damp Rated

### Product Dimensions

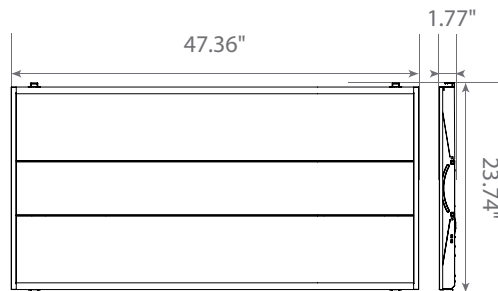

### Product Photometric Data

