


## Quartz Crystal


SMD-version

model	KX – 6T
frequency	26,0 MHz
mode	fundamental
operating temperature	-40° ~ +85°C
frequency tolerance at +25°C	± 30 ppm
temperature tolerance -40° ~ +85°C	±100 ppm
load capacitance $C_L$	10 pF
series resonance R1 max.	80 Ohm
aging at 25°C ( first year ) max.	± 2 ppm
shunt capacitance $C_0$ max.	3,5 pF
drive level max.	50 $\mu$ W typ., 100 $\mu$ W max.
contents of reel	1000 pcs.
part no.	12.86533


### Dimensions (mm):

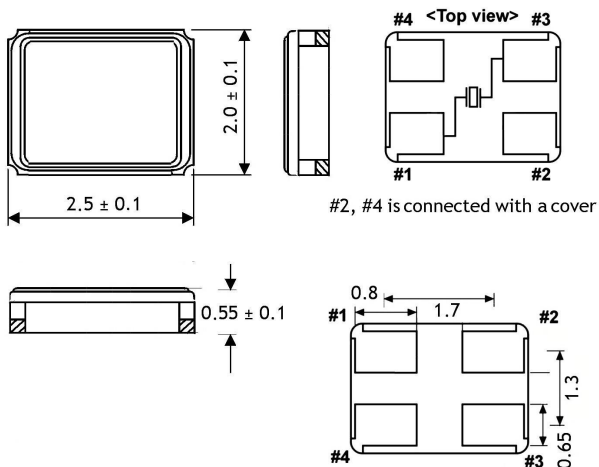


### Suggested soldering pad:

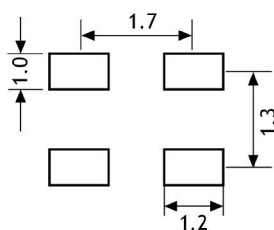

### Reflow soldering condition:

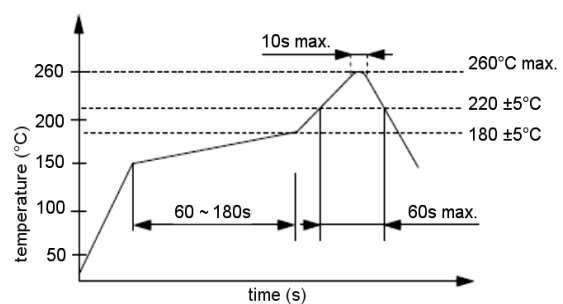

### Tape specification:

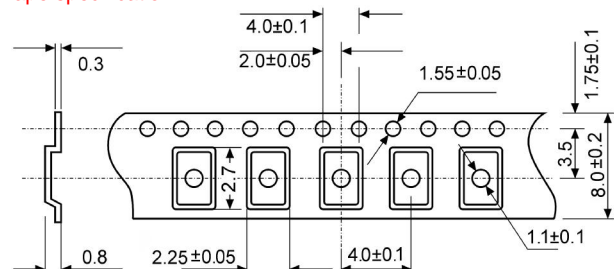

reel diameter 178 mm