


# Uninterruptible power supply replacement battery - UPS-BAT-KIT-VRLA 2X12V/38AH - 2908237

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Replacement battery for UPS-BAT/VRLA... energy storage

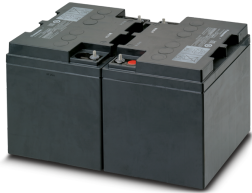

## Key Commercial Data

Packing unit	1 pc
GTIN	 4 055626 297750
GTIN	4055626297750
Weight per Piece (excluding packing)	25.360 g
Custom tariff number	85072080
Country of origin	China

## Technical data

### Dimensions

Width	330 mm
Height	175 mm
Depth	175 mm

### Ambient conditions

Ambient temperature (operation)	0 °C ... 40 °C
Ambient temperature (storage/transport)	0 °C ... 40 °C
Max. permissible relative humidity (operation)	≤ 95 %

### Input data

Nominal input voltage	2x 12 V DC
-----------------------	------------

# Uninterruptible power supply replacement battery - UPS-BAT-KIT-VRLA 2X12V/38AH - 2908237

## Technical data

### General

IQ technology	no
---------------	----

## Drawings

Pictogram



## Classifications

### eCl@ss

eCl@ss 10.0.1	27059290
eCl@ss 11.0	27059090
eCl@ss 5.1	27040603
eCl@ss 6.0	27059200
eCl@ss 7.0	27059290
eCl@ss 9.0	27059290

### ETIM

ETIM 6.0	EC002839
----------	----------

### UNSPSC

UNSPSC 18.0	26111710
-------------	----------

# Uninterruptible power supply replacement battery - UPS-BAT-KIT-VRLA 2X12V/38AH - 2908237

## Classifications

### UNSPSC

UNSPSC 19.0	26111710
UNSPSC 20.0	26111710
UNSPSC 21.0	26111710

## Approvals

### Approvals

---

Approvals


GOST-R

---

Ex Approvals

---

### Approval details

GOST-R		ROSS DE.BL08.D00191
--------	---	------------------------

---