




CSB-M1240M1240

SPLITTERS

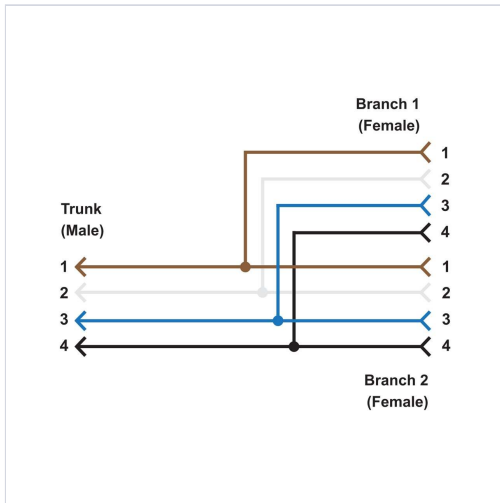


Splitter M12M to M12F and M12F connectors

4-pin, Non-Shielded, IP67, AWG 22

Black PUR cord, Straight Connectors

Splitter Length: 0 m

Part Number: 64206

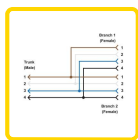

SPECIFICATIONS

IP Rating	IP67
Shield/No Shield	No Shield
Wiring	Parallel
Branches: Genders	Female, Female
Branches: Orientations	Straight, Straight
Splitter: Overmold Material and Color	PUR Black
Trunk Length (m)	0.00
Branches: Number of Contacts	4, 4

Chat with an Expert

Number of Branches	2
Voltage Rating (V)	250 V ac/dc
Maximum Temp. (Celsius)	105
Current Rating (A)	4.0
Trunk: Orientation	Straight
Trunk: Number of Contacts	4
Trunk: Connector Type	M12
Trunk: Gender	Male
Minimum Temp. (Celsius)	-40
Branches: Connector Types	Cookies M12, M12

By accepting cookies, we give you the best experience throughout our site, including access to My Account, My Library, and My Wish List.

To learn more, visit our [privacy policy](#).



Banner Engineering Corp. | 9714 Tenth Avenue North | Minneapolis, MN 55441 | United States of America

Chat with an Expert