

**AideTek® SMD 0603 size 100 values 50pc/value capacitor kit C06-50**

**0603 size, 100 values, 50pcs/value total 5000pcs filled in Aidetek BOX-ALL-144 from to 0.5pF to 10uF**

**Quick + easy to access all 100 values in a compact enclosure using tweezers.**

**Below is the value list and part number:**

Capacitance	Dielectric	Tolerance	Voltage (V)	Parts Number	Manufacturer
0.5pF	COG	± 0.25pF	50V	0603CG 0R5 C500NT	FH
1.0pF	COG	± 0.25pF	50V	TCC0603COG 1R0 C500CT	CCTC
1.2pF	COG	± 0.25pF	50V	TCC0603COG 1R2 C500CT	CCTC
1.5pF	COG	± 0.25pF	50V	TCC0603COG 1R5 C500CT	CCTC
1.8pF	COG	± 0.25pF	50V	0603CG 1R8 C500NT	FH
2.0pF	COG	± 0.25pF	50V	TCC0603COG 2R0 C500CT	CCTC
2.2pF	NPO	± 0.25pF	50V	0603N 2R2 C500CT	WALSIN
2.7pF	COG	± 0.25pF	50V	0603CG 2R7 C500NT	FH
3.0pF	COG	± 0.25pF	50V	0603CG 3R0 C500NT	FH
3.3pF	COG	± 0.25pF	50V	TCC0603COG 3R3 C500CT	CCTC
3.9pF	COG	± 0.25pF	50V	TCC0603COG 3R9 C500CT	CCTC
4.7pF	COG	± 0.25pF	50V	TCC0603COG 4R7 C500CT	CCTC
5.0pF	COG	± 0.25pF	50V	TCC0603COG 5R0 C500CT	CCTC
5.6pF	COG	± 0.25pF	50V	0603CG 5R6 C500NT	FH
6.8pF	COG	± 0.25pF	50V	TCC0603COG 6R8 C500CT	CCTC
8.2pF	COG	± 0.25pF	50V	TCC0603COG 8R2 C500CT	CCTC
10pF	COG	± 5%	50V	TCC0603COG 100 J500CT	CCTC
12pF	COG	± 5%	50V	TCC0603COG 120 J500CT	CCTC
15pF	COG	± 5%	50V	TCC0603COG 150 J500CT	CCTC
18pF	COG	± 5%	50V	TCC0603COG 180 J500CT	CCTC
22pF	COG	± 5%	50V	TCC0603COG 220 J500CT	CCTC
27pF	COG	± 5%	50V	TCC0603COG 270 J500CT	CCTC
33pF	COG	± 5%	50V	0603CG 330 J500NT	FH
39pF	COG	± 5%	50V	0603CG 390 J500NT	FH
47pF	COG	± 5%	50V	TCC0603COG 470 J500CT	CCTC
51pF	COG	± 5%	50V	TCC0603COG 510 J500CT	CCTC
56pF	COG	± 5%	50V	TCC0603COG 560 J500CT	CCTC
68pF	COG	± 5%	50V	TCC0603COG 680 J500CT	CCTC
82pF	COG	± 5%	50V	TCC0603COG 820 J500CT	CCTC
100pF	COG	± 5%	50V	TCC0603COG 101 J500CT	CCTC
150pF	COG	± 5%	50V	TCC0603COG 151 J500CT	CCTC
180pF	NPO	± 5%	50V	C0603JR NPO 9BN 181	YAGEO
220pF	NPO	± 5%	50V	0603N 221 J500CT	WALSIN
270pF	COG	± 5%	50V	TCC0603COG 271 J500CT	CCTC
330pF	NPO	± 5%	50V	0603N 331 J500CT	WALSIN
390pF	COG	± 5%	50V	TCC0603COG 391 J500CT	CCTC
470pF	NPO	± 5%	50V	0603N 471 J500CT	WALSIN



PO BOX 2426  
Monrovia, CA 91017  
U. S. A.

Tel.: (408) 329-7985  
Fax: (866) 571-5680  
[www.aidetek.com](http://www.aidetek.com) support@aidetek.com

560pF	COG	± 5%	50V	TCC0603COG 561 J500CT	CCTC
680pF	COG	± 10%	50V	TCC0603COG 681 K500CT	CCTC
820pF	X7R	± 10%	50V	TCC0603X7R 821 K500CT	CCTC
1.0nF	X7R	± 10%	50V	0603B 102 K500CT	WALSIN
1.2nF	X7R	± 10%	50V	TCC0603X7R 122 K500CT	CCTC
220pF	X7R	± 10%	50V	TCC0603X7R 221 K500CT	CCTC
270pF	X7R	± 10%	50V	TCC0603X7R 271 K500CT	CCTC
330pF	X7R	± 10%	50V	TCC0603X7R 331 K500CT	CCTC
390pF	X7R	± 10%	50V	0603B 391 K500NT	FH
470pF	X7R	± 10%	50V	0603B 471 K500NT	FH
560pF	X7R	± 10%	50V	TCC0603X7R 561 K500CT	CCTC
680pF	X7R	± 10%	50V	TCC0603X7R 681 K500CT	CCTC
820pF	X7R	± 10%	50V	TCC0603X7R 821 K500CT	CCTC
1.0nF	X7R	± 10%	50V	TCC0603X7R 102K500CTS	CCTC
1.2nF	X7R	± 10%	50V	TCC0603X7R 122 K500CT	CCTC
1.5nF	X7R	± 10%	50V	TCC0603X7R 152 K500CT	CCTC
1.8nF	X7R	± 10%	50V	0603B 182 K500NT	FH
2.2nF	X7R	± 10%	50V	TCC0603X7R 222 K500CT	CCTC
2.7nF	X7R	± 10%	50V	TCC0603X7R 272 K500CT	CCTC
3.3nF	X7R	± 10%	50V	TCC0603X7R 332 K500CT	CCTC
3.9nF	X7R	± 10%	50V	TCC0603X7R 392 K500CT	CCTC
4.7nF	X7R	± 10%	50V	TCC0603X7R 472 K500CT	CCTC
5.6nF	X7R	± 10%	50V	0603B 562 K500CT	WALSIN
6.8nF	X7R	± 10%	50V	TCC0603X7R 682 K500CT	CCTC
8.2nF	X7R	± 10%	50V	0603B 822 K500NT	FH
10nF	X7R	± 10%	50V	0603B 103 K500NT	FH
12nF	X7R	± 10%	50V	TCC0603X7R 123 K500CT	CCTC
15nF	X7R	± 10%	50V	TCC0603X7R 153 K500CT	CCTC
18nF	X7R	± 10%	50V	TCC0603X7R 183 K500CT	CCTC
22nF	X7R	± 10%	50V	TCC0603X7R 223 K500CT	CCTC
27nF	X7R	± 10%	50V	TCC0603X7R 273 K500CT	CCTC
33nF	X7R	± 10%	50V	TCC0603X7R 333 K500CT	CCTC
39nF	X7R	± 10%	50V	TCC0603X7R 393 K500CT	CCTC
47nF	X7R	± 10%	50V	TCC0603X7R 473 K500CT	CCTC
56nF	X7R	± 10%	50V	TCC0603X7R 563 K500CT	CCTC
68nF	X7R	± 10%	50V	TCC0603X7R 683 K500CT	CCTC
82nF	X7R	± 10%	50V	TCC0603X7R 823 K500CT	CCTC
100nF	X7R	± 10%	50V	C0603KR X7R 9BB 104	YAGEO
150nF	X7R	± 10%	50V	TCC0603X7R 154 K500CT	CCTC
220nF	X7R	± 10%	50V	TCC0603X7R 224 K500CT	CCTC
470nF	X7R	± 10%	25V	TCC0603X7R 474 K250CT	CCTC
1.0uF	X5R	± 10%	16V	CL10A 105KO8NNNC	SAMSUNG
10nF	X7R	± 10%	50V	0603B 103 K500NT	FH
12nF	X7R	± 10%	50V	TCC0603X7R 123 K500CT	CCTC
15nF	X7R	± 10%	50V	TCC0603X7R 153 K500CT	CCTC
18nF	X7R	± 10%	50V	TCC0603X7R 183 K500CT	CCTC
22nF	X7R	± 10%	50V	TCC0603X7R 223 K500CT	CCTC
27nF	X7R	± 10%	50V	TCC0603X7R 273 K500CT	CCTC
33nF	X7R	± 10%	50V	0603B 333 K500CT	WALSIN
39nF	X7R	± 10%	50V	TCC0603X7R 393 K500CT	CCTC
47nF	X7R	± 10%	50V	0603B 473 K500CT	WALSIN
56nF	X7R	± 10%	50V	C0603KR X7R 9BB 563	YAGEO
68nF	X7R	± 10%	50V	TCC0603X7R 683 K500CT	CCTC
82nF	X7R	± 10%	50V	TCC0603X7R 823 K500CT	CCTC
100nF	Y5V	+80% -20%	50V	0603F 104 Z500CT	WALSIN
150nF	X7R	± 10%	50V	TCC0603X7R 154 K500CT	CCTC
220nF	X7R	± 10%	50V	TCC0603X7R 224 K500CT	CCTC
330nF	X7R	± 10%	25V	CS1608X7R 334 K250NRB	SAMWHA
470nF	X7R	± 10%	25V	CS1608X7R 474 K250NRB	SAMWHA



PO BOX 2426  
Monrovia, CA 91017  
U. S. A.

Tel.: (408) 329-7985  
Fax: (866) 571-5680  
[www.aidetek.com](http://www.aidetek.com) support@aidetek.com

1.0uF	X5R	± 10%	16V	CL10A 105 K08NNNC	SAMSUNG
2.2uF	X5R	± 10%	10V	CL10A 225 KP8NNNC	SAMSUNG
4.7uF	X5R	± 10%	6.3V	CL10A 475 KQ8NNNE	SAMSUNG
10uF	X5R	± 20%	6.3V	CL10A 106 MQ8NNNC	SAMSUNG

**Below are the labels for this C06-50 capacitor kit**


<b>0.5pF</b> <b>NC50</b>	<b>1.0pF</b> <b>NC50</b>	<b>1.2pF</b> <b>NC50</b>	<b>1.5pF</b> <b>NC50</b>	<b>1.8pF</b> <b>NC50</b>	<b>2.0pF</b> <b>NC50</b>	<b>2.2pF</b> <b>NC50</b>	<b>2.7pF</b> <b>NC50</b>	<b>3.0pF</b> <b>NC50</b>
<b>3.3pF</b> <b>NC50</b>	<b>3.9pF</b> <b>NC50</b>	<b>4.7pF</b> <b>NC50</b>	<b>5.0pF</b> <b>ND50</b>	<b>5.6pF</b> <b>ND50</b>	<b>6.8 pF</b> <b>ND50</b>	<b>8.2pF</b> <b>ND50</b>	<b>10pF</b> <b>NJ50</b>	<b>12pF</b> <b>NJ50</b>
<b>15pF</b> <b>NJ50</b>	<b>18pF</b> <b>NJ50</b>	<b>22pF</b> <b>NJ50</b>	<b>27pF</b> <b>NJ50</b>	<b>33pF</b> <b>NJ50</b>	<b>39pF</b> <b>NJ50</b>	<b>47pF</b> <b>NJ50</b>	<b>51pF</b> <b>NJ50</b>	<b>56pF</b> <b>NJ50</b>
<b>68pF</b> <b>NJ50</b>	<b>82pF</b> <b>NJ50</b>	<b>100pF</b> <b>NJ50</b>	<b>150pF</b> <b>NJ50</b>	<b>180pF</b> <b>NJ50</b>	<b>220pF</b> <b>NJ50</b>	<b>270pF</b> <b>NJ50</b>	<b>330pF</b> <b>NJ50</b>	<b>390pF</b> <b>NJ50</b>
<b>470pF</b> <b>NJ50</b>	<b>560pF</b> <b>NJ50</b>	<b>680pF</b> <b>NJ50</b>	<b>820pF</b> <b>NJ50</b>	<b>1.0nF</b> <b>NJ50</b>	<b>1.2nF</b> <b>NJ50</b>	<b>220pF</b> <b>XK50</b>	<b>270pF</b> <b>XK50</b>	<b>330pF</b> <b>XK50</b>
<b>390pF</b> <b>XK50</b>	<b>470pF</b> <b>XK50</b>	<b>560pF</b> <b>XK50</b>	<b>680pF</b> <b>XK50</b>	<b>820pF</b> <b>XK50</b>	<b>1.0nF</b> <b>XK50</b>	<b>1.2nF</b> <b>XK50</b>	<b>1.5nF</b> <b>XK50</b>	<b>1.8nF</b> <b>XK50</b>
<b>2.2nF</b> <b>XK50</b>	<b>2.7nF</b> <b>XK50</b>	<b>3.3nF</b> <b>XK50</b>	<b>3.9nF</b> <b>XK50</b>	<b>4.7nF</b> <b>XK50</b>	<b>5.6nF</b> <b>XK50</b>	<b>6.8nF</b> <b>XK50</b>	<b>8.2nF</b> <b>XK50</b>	<b>10nF</b> <b>XK50</b>
<b>12nF</b> <b>XK50</b>	<b>15nF</b> <b>XK50</b>	<b>18nF</b> <b>XK50</b>	<b>22nF</b> <b>XK50</b>	<b>27nF</b> <b>XK50</b>	<b>33nF</b> <b>XK50</b>	<b>39nF</b> <b>XK50</b>	<b>47nF</b> <b>XK50</b>	<b>56nF</b> <b>XK50</b>
<b>68nF</b> <b>XK50</b>	<b>82nF</b> <b>XK50</b>	<b>100nF</b> <b>XK50</b>	<b>150nF</b> <b>XK50</b>	<b>220nF</b> <b>XK50</b>	<b>470nF</b> <b>XK50</b>	<b>1.0uF</b> <b>XK50</b>	<b>10nF</b> <b>YM50</b>	<b>12nF</b> <b>YM50</b>
<b>15nF</b> <b>YM50</b>	<b>18nF</b> <b>YM50</b>	<b>22nF</b> <b>YM50</b>	<b>27nF</b> <b>YM50</b>	<b>33nF</b> <b>YM50</b>	<b>39nF</b> <b>YM50</b>	<b>47nF</b> <b>YM50</b>	<b>56nF</b> <b>YM50</b>	<b>68nF</b> <b>YM50</b>
<b>82nF</b> <b>YM50</b>	<b>100nF</b> <b>YM50</b>	<b>150nF</b> <b>YM50</b>	<b>220nF</b> <b>YM25</b>	<b>330nF</b> <b>YM25</b>	<b>470nF</b> <b>YM25</b>	<b>1.0uF</b> <b>YM10</b>	<b>2.2uF</b> <b>YM10</b>	<b>4.7uF</b> <b>YZ10</b>
<b>10uF</b> <b>YZ06</b>								



PO BOX 2426  
Monrovia, CA 91017  
U. S. A.

Tel.: (408) 329-7985  
Fax: (866) 571-5680  
[www.aidetek.com](http://www.aidetek.com) support@aidetek.com

**Below is the AideTek® Multilayer ceramic SMD Capacitor kits Codes Meaning:**

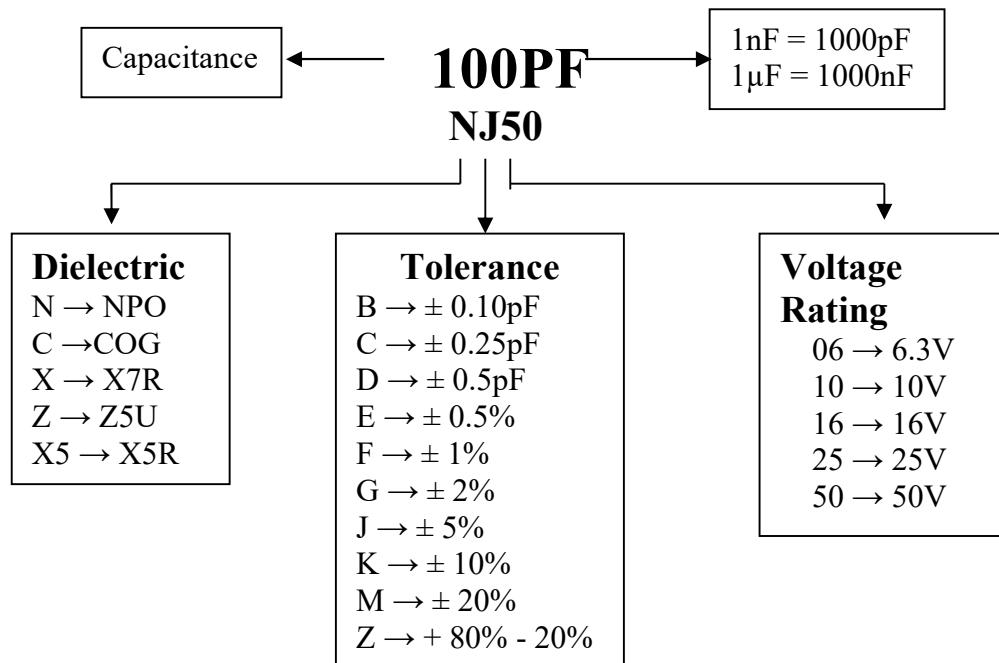

**Click below to download the manufacturer's datasheet:**

[https://www.aidetek.com/AideTek\\_MLCC\\_sunsung\\_capacitor\\_datasheet.pdf](https://www.aidetek.com/AideTek_MLCC_sunsung_capacitor_datasheet.pdf)

[https://www.aidetek.com/AideTek\\_CTCC\\_capacitor\\_datasheet.pdf](https://www.aidetek.com/AideTek_CTCC_capacitor_datasheet.pdf)

[https://aidetek.com/AideTek\\_YAGEO\\_capacitor\\_datasheet.pdf](https://aidetek.com/AideTek_YAGEO_capacitor_datasheet.pdf)

[https://aidetek.com/AideTek\\_Walsin\\_capacitor\\_datasheet.pdf](https://aidetek.com/AideTek_Walsin_capacitor_datasheet.pdf)

[https://aidetek.com/AideTek\\_Samwha\\_capacitor\\_datasheet.pdf](https://aidetek.com/AideTek_Samwha_capacitor_datasheet.pdf)