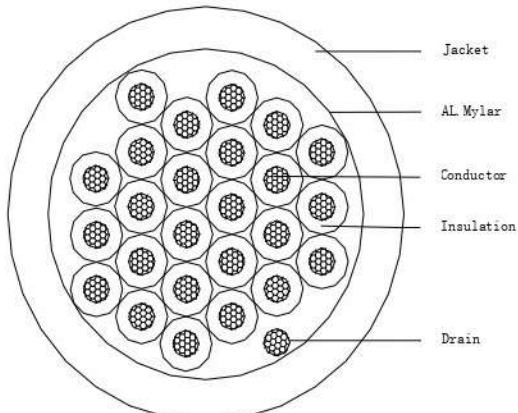


# CompuCableUSA

Providing Connectivity Solutions

specification		UL2464 26AWG*25C+D+AL. Mylar, OD:8.0mm Gray PVC HALF MATT			Picture	
Item		25C				
Conductor	AWG	26AWG				
	Material	Tinned copper				
	Cond. Size	7/0.16TC±0.008mm				
Insulation	Avg. Thick	0.23mm Ref			Note	
	Material	SR-PVC				
	O. D	1.00±0.05mm				
	Color	1. BLACK; 2. BROWN; 3. RED; 4. ORANGE; 5. YELLOW; 6. GREEN; 7. BLUE; 8. PURPLE; 9. GRAY; 10. WHITE; 11. PINK; 12. LIGHT GREEN; 13. BLACK/WHITE; 14. BROWN/WHITE; 15. RED/WHITE; 16. ORANGE/WHITE; 17. GREEN/WHITE 18. BLUE/WHITE 19. PURPLE/WHITE; 20. RED/BLACK 21. ORANGE/BLACK 22. YELLOW/BLACK; 23. GREEN/BLACK 24. GRAY/BLACK 25. PINK/BLACK				
intertwist	Drain	7/0.20TC±0.008mm Tinned copper				
	aluminum foil AL	25u*35±5mm >25% MIN				
Braid	Cond. Size	/				
	Shield Coverage	/				
Jacket	Material Color	PVC N9C03016 VW-1/60P Gray (PT:430C)			Rev	A/0:
	O. D	8.0±0.15mm			Customer	CompuCablePlusUSA
	Surface	HALF MATT			Part.No:	BW-26AL-25G1K
Marking	E134689 AWM 2464 80°C 300V VW-1 (1") RoHS (1") RoHS2.0 (1") REACH (1") COMPLIANT				Part.No:	
	height: 1.2MM	Color: BLACK	font: C1-18	(1")	Rev:	
					Data:	