




GREENLEE.
A Textron Company

MADE FOR THE TRADE!™

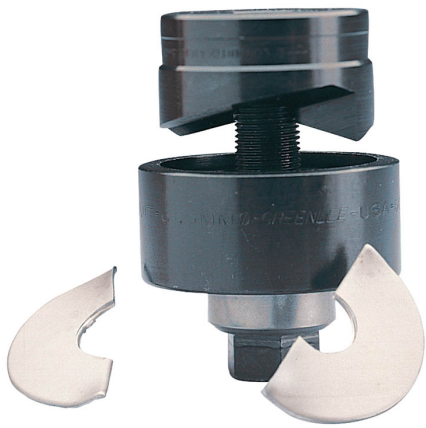

PUNCH UNIT 12.5MM

Slug-Buster Knockout Punches 0.492 to 2.520

Cat No: 06727

UPC No: 783310067276

Description

- "The contractor's choice - worldwide
- Unique punch profile also splits slugs for easier slug removal
- Use with battery-powered, hydraulic, ratchet or manual drivers
- Uses standard Greenlee dies and draw studs
- Slug Buster punches available in sizes up thru 2.52" (64.0 mm)
- U.S. Patent #4,543,722 for Slug-Buster "

Specifications

- Application : For Punch Mild Steel, Aluminum, Fiberglass And Plastic
- Capacity Mild Steel : 16 GA (1.500 MM)
- Includes : Punch, Die And Draw Stud
- ISO : 12
- Operation Type : Battery, Hydraulic, Ratchet or Manual Drivers
- PG : 7
- Replacement Part : 06728 UPC 06728 Punch, 06729 UPC 06729 Die And 1675AV UPC 04218 Draw Stud
- Size : 0.492 IN (12.500 MM)
- Sub Brand : Slug-Buster
- Type : Knockout
- Weight : 0.300 LB (137.000 GM)