



ISL Products International

Electronic Ballast for UV Bulbs
24VAC - "PS" Program Start
P.S-I-45415-A

This electronic ballast is designed with a program start feature that extends the life of different ultraviolet quartz germicidal lamps. It's equipped with push style terminals for seamless installation and is tested to UL 935 standards with Intertek approvals.





Contact Us for alternative solutions!



Electrical Specifications			
Lamp Type:	GPH212T5	GPH287T5	GPH357T5
Input Voltage:	24VAC	24VAC	24VAC
Lamps Operated:	1	1	1
Input Power (W):	14.28	18.86	24.55
Line Current (A):	0.738	0.789	1.023
Power Factor:	0.086	0.996	0.997
THD:	8	7.1	6.3
Lamp Voltage (V):	25	34	42
Ballast Type:	Program Start (PS)		Lamp Current: 420mA (+/- 10%)
Current Crest Factor:	< 1.7		Voltage Transients: ANSI 62.41

Environmental Specifications			
Sound Rating:	Class A	Min. Operating Temp:	0°C / 32°F
Weight	12.9 oz	Max. Case Temp:	70°C / 158°F

Protections			
Input Protection:	Fuse	Approvals:	UL.935 / CSA.C22.2
Output Protection	EOL		Class "P"/1 Outdoor

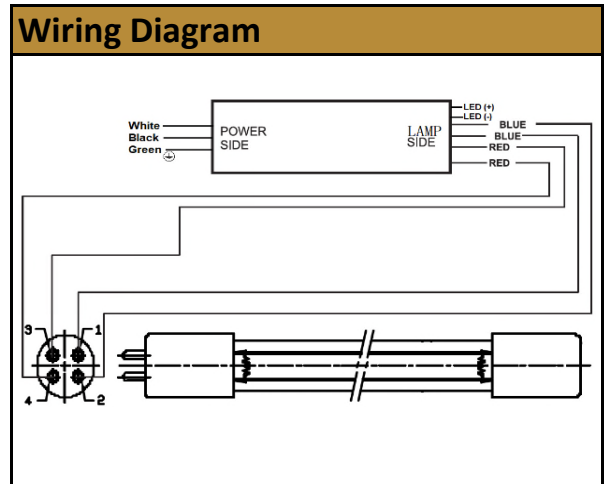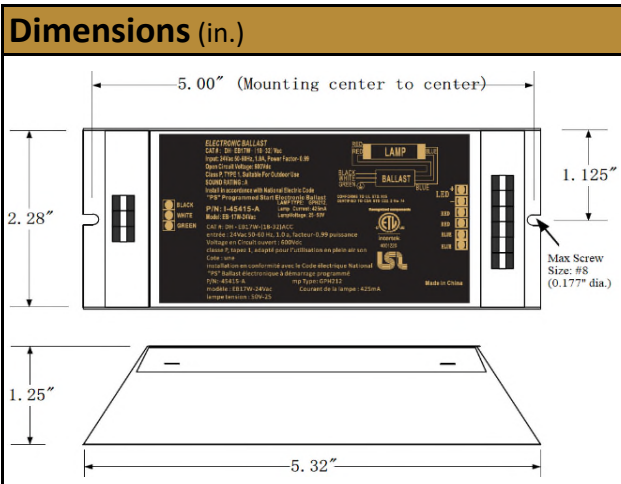

© 2020 ISL Products International Ltd. Specifications subject to change without notice.

