



Lithium Coin Cell - CR 2325

- Reliable energy for your application
- Standard cells and customized packs
- ESD protection
- UL recognized
- Battery Certification Experts



RoHS compliant



Pb free



REACH compliant



Conflict mineral free


Technical Data Sheet · CR 2325

SPECIFICATIONS


Nominal Voltage	3V
Jauch part number	249999 (1pc blister)
Nominal Capacity	220 mAh
Standard Load	15 kΩ
Standard Current	0.2 mA
Max. Continuous Current	3 mA
Max. Pulse Current	18 mA
Operating Temperature	-30°C to +70°C*
Weight	Approx. 3.2 gr.
Chemistry	Li/MnO ₂
UL1642	MH62838

* In applications where the battery is exposed to temperatures >70°C, please contact Jauch.


DIMENSIONS

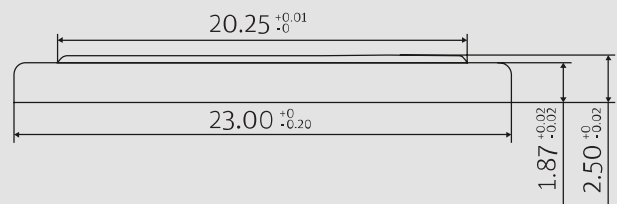

DISCHARGE CHARACTERISTICS

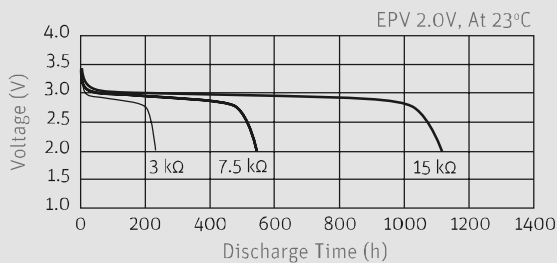

TEMPERATURE CHARACTERISTICS

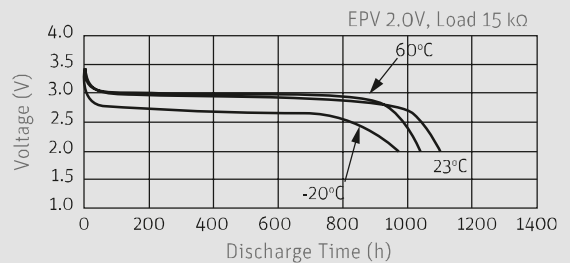

Wide assortment of mounting options, including through hole, surface mount and wire terminals.

Contact Jauch for more information
batterytechnology@jauch.com