


WJ45H
BARRIER TERMINAL BLOCK

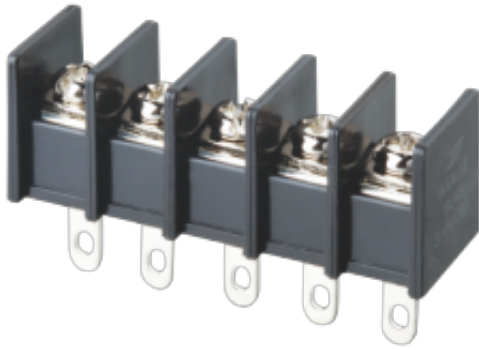

Material

Screws	M4.0 Steel Ni plated
Pin Header	Copper alloy , Sn plated
Housing	PA66 , UL94V-0

Electrical

Standard	UL	IEC
Rated Voltage	300V	400V
Rated current	20A	24A
Wire range	22-12AWG	2.5mm ²
Contact Resistance	20mΩ	
Insulation resistance	500MΩ/DC500V	
Withstanding voltage	AC2000V/1Min	

Other Data

Pitch/Poles [mm]/[P]	9.5/2-24
Operating temperature [°C]	-40°C~+105°C
Torque	12.24Kgf.cm/1.2Nm/10.6Lb.in

Dimensions

PCB opening diagram

