

TKG-086-MB-IP68-BLACK

InduProof³



PRODUCT FEATURES

- Silicone keyboard with 86 keys
- Integrated mousebutton
- Aluminium bottom plate
- IP68 protection, can be submerged into liquids
- VESA mounting available on request
- Flat key shape

SPECIFICATION

Number of keys:	86	Dimensions:	320 x 145 x 22.6 mm
Housing type:	desktop housing	Weight:	1000 g
Material housing / bottom:	silicone / aluminium	Compliance:	
Keyswitch technology:	gold plated metal domes	-- Europe:	CE
Switching cycles:	approx. 1 mill. (per key)	-- USA/Canada:	FCC Part 15 Class B
Operating force:	3.0 N	-- Global:	REACH, RoHS self-declaration
Switch travel:	0.6 mm		
Protection level:	IP68		
Interface:	USB		
USB compatibility:	USB V1.1/2.0 compliance		
Operating temperature:	0 °C to +70 °C		
Storage temperature:	-25 °C to +80 °C		

SPECIFICATION MOUSEBUTTON




Operating principle:	hall effect
Resolution:	800 dpi

Cat.No.	Product description	Layout
KG13006	TKG-086-MB-IP68-BLACK-USB-DE	German
KG13007	TKG-086-MB-IP68-BLACK-USB-US	US

Other language versions / interfaces / configurations available on request.

Subject to modifications and errors

TECHNICAL DRAWING (in mm)

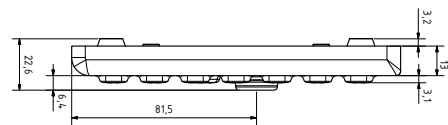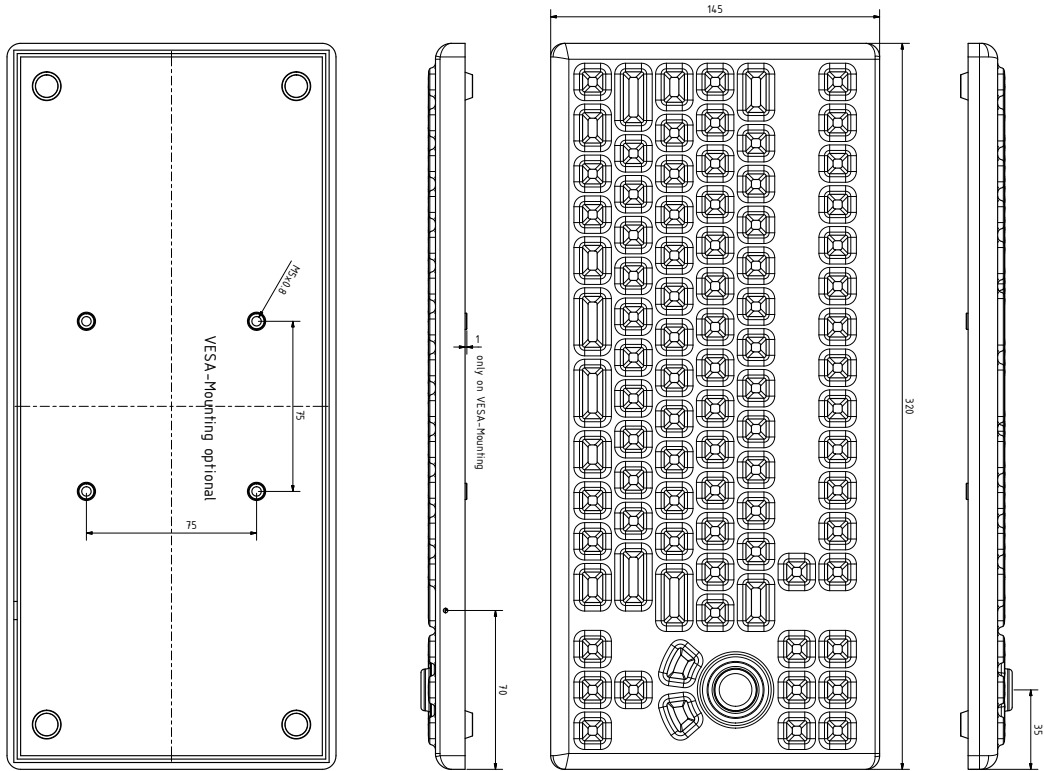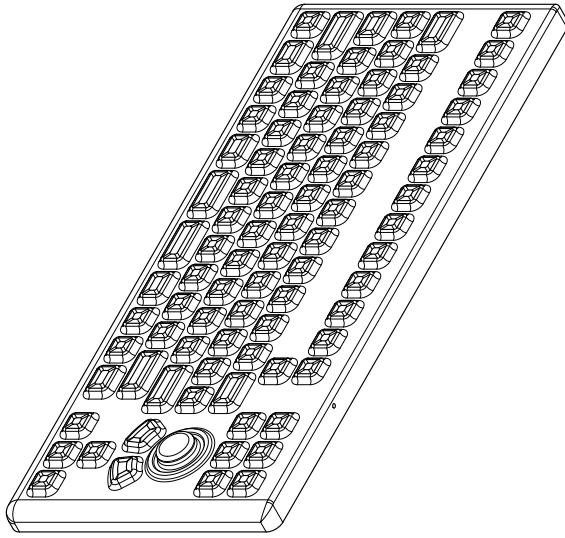

Subject to modifications and errors

GETT Gerätetechnik GmbH

Mittlerer Ring 1 | 08233 Treuen | Germany
 Tel: +49 37468 660-0
 Fax: +49 37468 660-66
 E-Mail: info@gett.de
 Internet: www.gett.de

Gett North America LLC

E-Mail: info@gett-na.com
 Internet: www.gett-na.com

Gett Asia Ltd.

E-Mail: info@gett-asia.com
 Internet: www.gett-asia.com