


## CLEANTYPE® MEDICAL

KSI-U10050 (WHITE)

KSI-U20050 (BLACK)

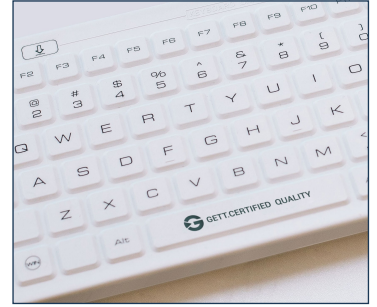

## SPECIAL FEATURES

- IP68 rated medical keyboard
- Adjustable brightness of backlight
- Fully washable and disinfectable
- 106 keys incl. num pad
- Waterproof silicone USB protection cap
- Excellent tactile feeling
- ON/OFF switch for keyboard power
- EN60601-1-2 certified

## SPECIFICATION

Number of keys:	106 (US-Layout)	Cable length:	190cm
Keyswitch technology:	Membrane	Operating temperature:	0°C ~ +55°C
Switching cycles:	Approx. 2 mill. (per key)	Storage temperature:	-30°C ~ +70°C
Protection level:	IP68	Dimensions:	380(L) x 130(W) x 13(T)mm
Housing material:	Silicone	Weight:	Approx. 869g
Housing color:	White & black	Warranty:	2 years
Backlight:	Blue color, adjustable brightness	Certification:	EN60601-1-2, CE, FCC, RoHS, REACH
Interfaces:	USB		

## ORDER INFORMATION

Cat. No.	Product Description	Color	Layout
KSI-U10050	CLEANTYPE® MEDICAL	White	US
KSI-U10050-DE	CLEANTYPE® MEDICAL	White	German
KSI-U10050-AR	CLEANTYPE® MEDICAL	White	Arabic
KSI-U10050-JP	CLEANTYPE® MEDICAL	White	Japanese
KSI-U10050-TH	CLEANTYPE® MEDICAL	White	Thai

Other layouts, configurations and interfaces on request.

## SUPPLEMENT PRODUCTS

Cat. No.	Product Description	Color
MSI-U10030	Waterproof medical touch scroll mouse	White
MSI-U20030	Waterproof medical touch scroll mouse	Black

## EN60601-1-2 CERTIFIED

EN 60601-1-2 applies to the basic safety and essential performance of Medical Equipment(ME) equipment and ME systems in the presence of electromagnetic disturbances and to electromagnetic disturbances emitted by ME equipment and ME systems.

## SHORT OPERATING INSTRUCTIONS



Turn the keyboard on and off by pressing both keys (duration 5 sec).



Turn the backlight on and off with this button.



Adjust the brightness level (down / up) with these buttons.

## CLEANING INSTRUCTION

For further details please refer to below link:

<https://gett-group.com/en/gett-service/cleaning-and-material-resistances>