


CLEANTYPE® EASY PROTECT

KSI-U10100 (WHITE)

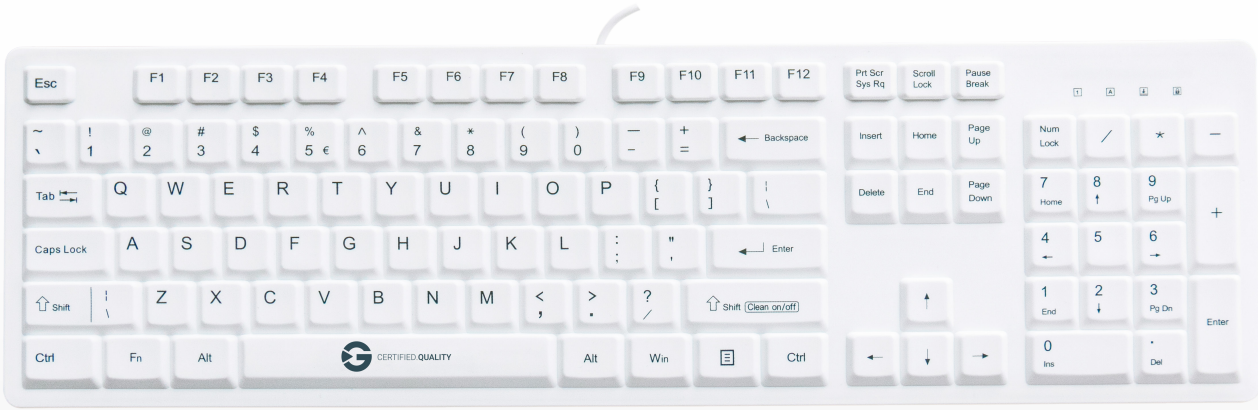

SPECIAL FEATURES

- IP68 rated medical keyboard
- 15 cm shorten cable with USB waterproof silicone cap
- 4 standard keyboard LEDs (Num, Scroll, Caps Lock, Clean Mode)
- Can be cleaned with common detergents
- Additional USB extension cable provided

SPECIFICATION

Number of keys:	105 (US-Layout)	Interfaces:	USB
Keyswitch technology:	Membrane	Cable length:	15cm with extension cable
Switching cycles:	Approx. 2 mill. (per key)	Operating temperature:	0°C ~ +55°C
Protection level:	IP68	Storage temperature:	-15°C ~ +60°C
Housing material:	Plastic	Dimensions:	440(L) x 130(W) x 25(T)mm
Skin material:	Silicone	Weight:	Approx. 492g
Housing color:	White	Warranty:	2 years
		Certification:	CE, FCC, RoHS, REACH

ORDER INFORMATION

Cat. No.	Product Description	Color	Layout
KSI-U10100	CLEANTYPE® EASY BASIC	White	US
KSI-U10100-DE	CLEANTYPE® EASY BASIC	White	German
KSI-U10100-AR	CLEANTYPE® EASY BASIC	White	Arabic
KSI-U10100-JP	CLEANTYPE® EASY BASIC	White	Japanese
KSI-U10100-TH	CLEANTYPE® EASY BASIC	White	Thai

Other layouts, configurations and interfaces on request.

SUPPLEMENT PRODUCTS

Cat. No.	Product Description	Color
MSI-U10030	Waterproof medical touch scroll mouse	White
MSI-U20030	Waterproof medical touch scroll mouse	Black

CLEANING INSTRUCTION

For further details please refer to below link:

<https://gett-group.com/en/gett-service/cleaning-and-material-resistances>