


CLEANTYPE® MEDICAL

KSI-U30051 (RED)

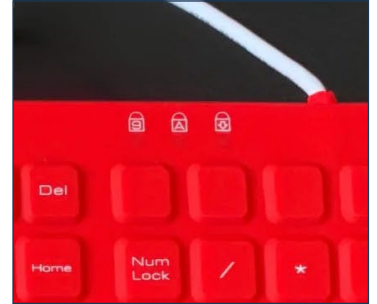

SPECIAL FEATURES

- IP68 rated medical keyboard
- Fully washable and disinfectable
- 110 keys incl. num pad
- Waterproof silicone USB protection cap
- Excellent tactile feeling
- ON/OFF switch for keyboard power

SPECIFICATION

Number of keys:	110 (US-Layout)	USB cap color:	White
Keyswitch technology:	Membrane	Cable length:	190cm
Switching cycles:	Approx. 2 mill. (per key)	Operating temperature:	0°C ~ +55°C
Protection level:	IP68	Storage temperature:	-30°C ~ +70°C
Housing material:	Silicone	Dimensions:	380 (L) x 130 (W) x 13 (T) mm
Housing color:	Red (code RAL#185C)	Weight:	Approx. 869g
Interfaces:	USB	Warranty:	2 years
USB cable color:	White	Certification:	CE, FCC, RoHS, REACH

ORDER INFORMATION

Cat. No.	Product Description	Color	Layout
KSI-U30051	CLEANTYPE® medical silicone keyboard (no magnet)	Red	US

Other layouts, configurations and interfaces on request.

SUPPLEMENT PRODUCTS

Cat. No.	Product Description	Color
MSI-U30050-LD	Waterproof compact medical click scroll mouse	Red

Other detections, configurations and interfaces on request.

CLEANING INSTRUCTION

For further details please refer to below link:

<https://gett-group.com/en/gett-service/cleaning-and-material-resistances>