

# TRACKIPRO

The long-endurance industrial asset tracker




## Unique Features

- **Real-Time Alerts:** Immediate location change alerts and multiple geofence setups.



Worldwide Coverage

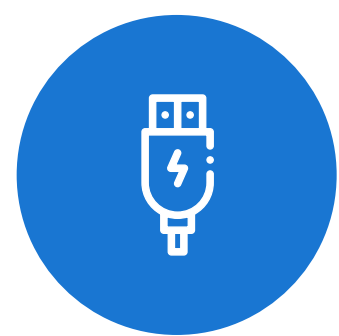

USB-C Charger




Speed Monitoring



Geofencing



Various Attachments

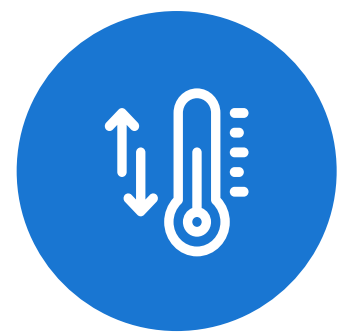

Temperature Sensor



Light Sensor



Durable & Waterproof




Ultra-Long  
Battery Life



One Account for Managing  
All of Your Devices

## Usage Examples

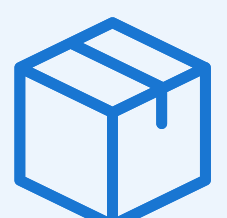

Cargo Monitoring



Industrial Theft  
Prevention



Fleet Management

## Specifications

## Trackipro

Stock Code	TRKM110-2G (2G) / TRKM110-3G (3G)
GSM Platform	MTK6250A (2G) / MTK6276 (3G)
GNSS	GPS, Glosnas, Galileo, Baidu
Bands	Quad GSM 850/ GSM900/ DCS1800/ PCS1900 (2G) GSM 850/ GSM900/ DCS1800/ PCS1900 / WCDMA 850/900/1900/2100 (3G)
Dimensions	90 mm x 64 mm x 34 mm (LxWxH)
Weight	300 gr
Active Battery Life	From 75 to 356 days, depends on mode of operation and cellular network conditions
Battery Type	IP67
Waterproof	Rechargeable Li-ion 10 000mAh
Operational Temperatures	-20 + 60 °C
USB Charger	USB Type-C charger
Microphone	Yes
Additional Sensors	Accelerometer
Wi - Fi	802.11b/g/n
Bluetooth	BT4.0

## Application features

## Trackipro

Full Data or Alert Only	Full Data
Maps	✓
Real Time Updates	✓
Geo Speed Alerts	✓
Geo Fence Alerts	✓
Travel History Available	Up to 365 days
Alerts	Email, SMS, Push
№ of Location Samples	Unlimited
Customizable Tracking	✓
Global Tracking	✓
SOS Alarm	✓

**Minimal Update Interval** 1 minute

**Play Sound** ✓

## Network & Data Transfer

### Trackipro

**Network Technology** GPRS (2G), HSPA(3G)

**Data Load** Full Tracking mode 35 bytes per minute

**Roaming Data** Yes

## GPS Specifications

### Trackipro

**GPS** GPS, Galileo, Glonass, Baidu

**Channels** 22 tracking, 66 acquisition

**Accuracy** Appx. 5m under open sky

**Acquisition Mode** Hot start < 2 sec, Cold start < 24 sec

**Data Encryption** Available

**Cached Memory** On board capacity for 1000 tracking points