


UNIVERSAL

All purpose, best-selling tracker

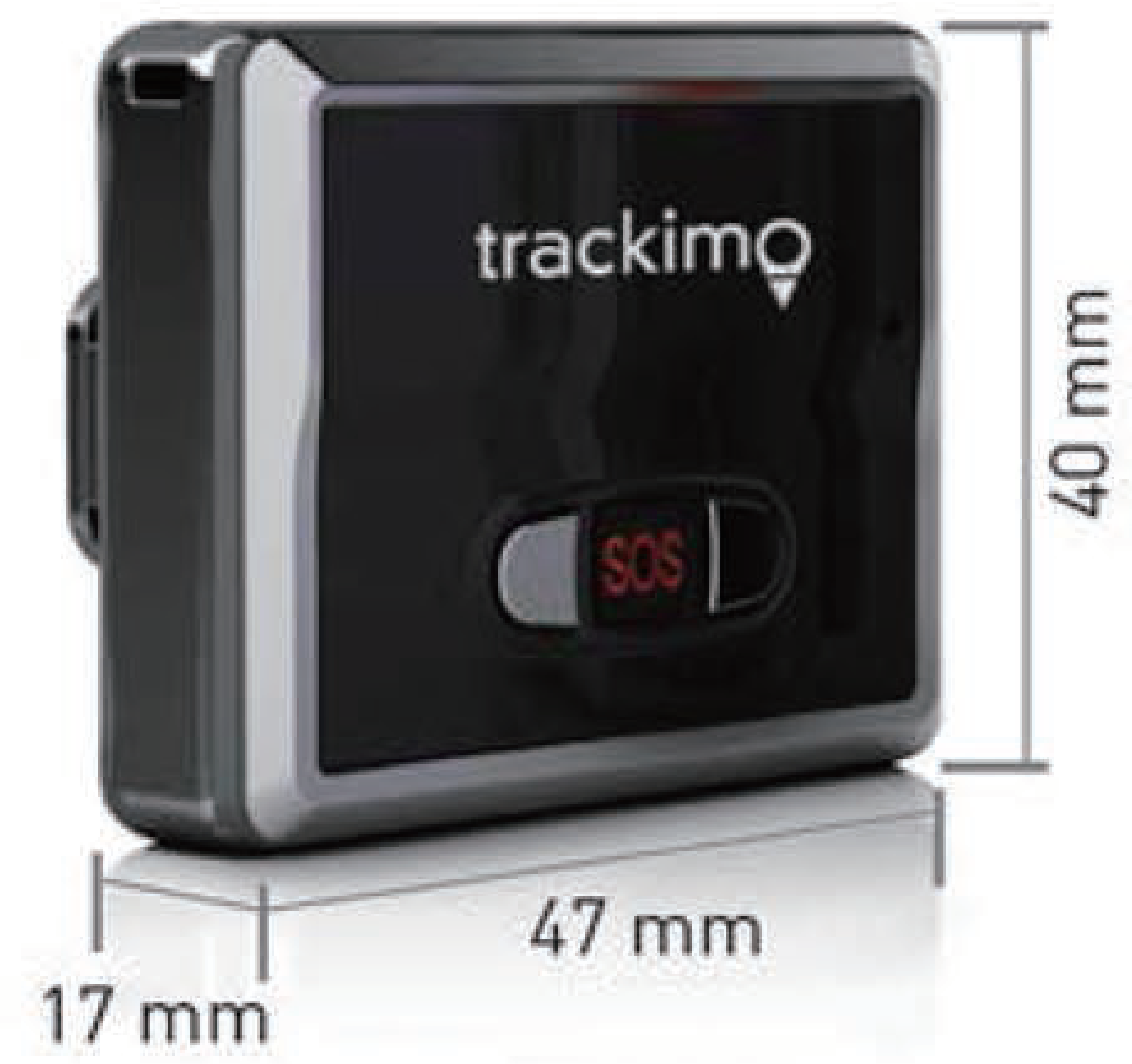

Unique Features

- **On-Board Connectivity:** All-round 12v/24v compatibility for your vehicle or boat.

- **Unlimited Connection:** Supports worldwide 2G/3G/4G connectivity.

- **Wide Range of Accessories:** For body wear, attachments, increased battery life and more.



Two

Programmable Buttons



SOS Button



Speed Monitoring



Geofencing



One Account for Managing
All of Your Devices



Waterproof

Usage Examples



Vehicles



Loved ones



Outdoor



Boats



Staff



Heavy-Duty Machinery

Specifications

Universal

Stock Code	TRKM004 (2G) / TRKM010 (3G)
GSM Platform	MTK6250A (2G) / MTK6276 (3G)
GNSS	GPS, Glosnas, Galileo, Baidu
Bands	Quad GSM 850/ GSM900/ DCS1800/ PCS1900 (2G) GSM 850/ GSM900/ DCS1800/ PCS1900 / WCDMA 850/900/1900/2100 (3G)
Sim Card	Embedded SIM
Application	iOS / Android / PC / Mac
Colors	Black
Dimensions	47 mm x 40 mm x 17 mm
Weight	42 gr
Active Battery Life	Up to 6 days, depends on mode of operation and cellular network conditions
Battery Type	Rechargeable Li-ion 600mAh
Operational Temperatures	-20 + 60 °C
Included Attachments	Strap, Clip, Velcro, Magnet, Lanyard
Vehicle Attachment Option	Not included. Installation Kit available.
Wi-Fi	802.11b/g/n
Bluetooth	BT4.0
Additional Sensors	Accelerometer
USB Charger	Micro USB 5 Volts 500 ma

Application features

Universal

Full Data or Alert Only	Full Data
Maps	✓
Real Time Updates	✓
Geo Speed Alerts	✓
Geo Fence Alerts	✓
Travel History Available	Up to 365 days
Alerts	Email, SMS, Push
Nº of Location Samples	Unlimited

Customizable Tracking	✓
Global Tracking	✓
SOS Alarm	✓
Minimal Update Interval	1 minute
Configurable Alert Button	✓
Play Sound	✓

Network & Data Transfer

Universal

Network Technology	GPRS (2G), HSPA(3G)
Data Load	Full Tracking mode 35 bytes per minute
Roaming Data	Yes
Roaming voice	Yes

GPS Specifications

Universal

GPS	GPS, Galileo, Glonass, Baidu
Channels	22 tracking, 66 acquisition
Accuracy	Appx. 5m under open sky
Acquisition Mode	Hot start < 2 sec, Cold start < 24 sec
Data Encryption	Available
Cached Memory	On board capacity for 1000 tracking points