


### 1210 AWG Vinyl Insulated Ring

**Material:** Tin Plated Copper with Butted Seam  
**Insulation Material:** Yellow PVC Vinyl with Funnel Entry  
**Maximum Electrical Current:** 50 Amps  
**Maximum Electrical Rating:** 75°C, 600V  
**Material Thickness (T):** .039

**Barrel ID (d1):** .134  
**Barrel OD (D):** .248     **J Type:** .276  
**Barrel Length (E):** .555     **J Type:** .551

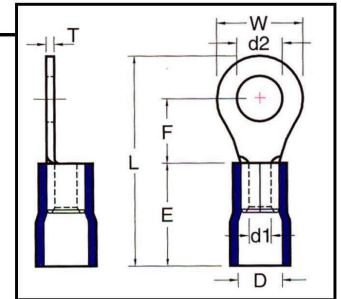


HOFFMAN PART NO.	STUD SIZE	DIMENSIONS (INCHES)					UL	TAPE MOUNTED REEL QTY	DIE FOR TAPE MOUNTED	HAND TOOL
		STUD DIAMETER	TONGUE WIDTH	STUD CLEARANCE	LENGTH					
		d2	W	F	L					
FVL1210-3R2/J	4	.126	.374	.327	1.063	Y	500	3V1210	YNT1210S	
FVL1210-S3R2	6	.146	.283	.240	.937	Y	500	3V1210	YNM2210	
FVL1210-S3/J	6	.146	.283	.232	.925	Y	500	3V1210	YNT1210S	
FVL1210-S4R2	8	.169	.283	.240	.937	Y	500	3V1210	YNM2210	
FVL1210-4/J	8	.169	.374	.327	1.063	Y	500	3V1210	YNT1210S	
FVL1210-4R2	8	.169	.374	.358	1.091	Y	500	3V1210	YNM2210	
FVL1210-5R2/J	10	.209	.374	.327	1.063	Y	500	3V1210	YNT1210S	
FVL1210-5R2	10	.209	.374	.327	1.067	Y	500	3V1210	YNM2210	
FVL1210-S6R2/J	1/4	.252	.520	.354	1.165	Y	500	3V1210	YNT1210S	
FVL1210-6R2/J	1/4	.252	.472	.512	1.299	Y	500	3V1210	YNT1210S	
FVL1210-6R2	1/4	.252	.472	.413	1.205	Y	500	3V1210	YNM2210	
FVL1210-S8R2/J	5/16	.331	.520	.354	1.165	Y	500	3V1210	YNT1210S	
FVL1210-8R2	5/16	.331	.591	.524	1.382	Y	500	3V1210	YNM2210	
FVL1210-9R2	3/8	.413	.591	.524	1.382	Y	500	3V1210	YNM2210	
FVL1210-9/J	3/8	.413	.591	.539	1.386	Y	500	3V1210	YNT1210S	
FVL1210-13	1/2	.512	.756	.630	1.563	Y	NA	NA	YNM2210	

## Vinyl Insulated Ring Terminals with Copper Support Sleeve

### 2216 AWG Vinyl Insulated Ring with Copper Support Sleeve

**Material:** Tin Plated Copper with Butted Seam  
**Insulation Material:** Red PVC Vinyl with Funnel Entry Copper Support Sleeve  
**Maximum Electrical Current:** 18 Amps  
**Maximum Electrical Rating:** 75°C, 600V  
**Material Thickness (T):** .030

**Barrel ID (d1):** .067  
**Barrel OD (D):** .065  
**Barrel Length (E):** .413

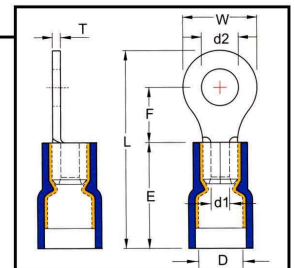

HOFFMAN PART NO.	STUD SIZE	DIMENSIONS (INCHES)					UL	TAPE MOUNTED REEL QTY	DIE FOR TAPE MOUNTED	HAND TOOL
		STUD DIAMETER	TONGUE WIDTH	STUD CLEARANCE	LENGTH					
		d2	W	F	L					
FVD2216-S3	4	.126	.217	.197	.709	Y	1000	3V2216	YNM2210D	
FVD2216-M3	6	.146	.260	.248	.783	Y	1000	3V2216	YNM2210D	
FVD2216-M4	8	.169	.260	.248	.783	Y	1000	3V2216	YNM2210D	
FVD2216-4	8	.169	.315	.276	.839	Y	1000	3V2216	YNM2210D	
FVD2216-5	10	.209	.315	.276	.839	Y	1000	3V2216	YNM2210D	
FVD2216-6	1/4	.252	.457	.433	1.075	Y	1000	3V2216	YNM2210D	
FVD2216-8	5/16	.331	.457	.433	1.075	Y	1000	3V2216	YNM2210D	
FVD2216-9	3/8	.413	.535	.547	1.220	Y	1000	3V2216	YNM2210D	

