


11 - Alligator Clips

Standard Alligator Clips

Material: Nickle Plated Iron, 800°C

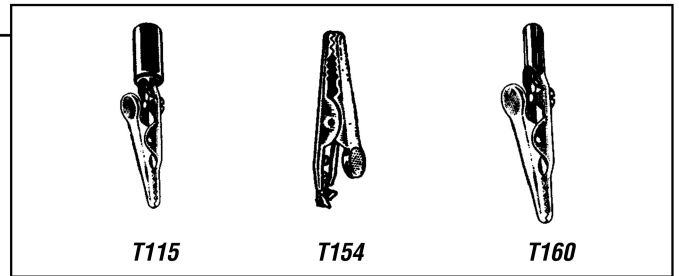

HOFFMAN PART NO.	AMPS	LENGTH	JAW SPREAD	JAW LENGTH	INSULATION
T115	10	1.97	0.509	0.157	None
T115SR	10	1.97	0.509	0.157	Red
T115SB	10	1.97	0.509	0.157	Black
T154	5	1.22	0.193	0.138	None
T160	10	1.97	0.509	0.157	None
T160R	10	1.97	0.509	0.157	Red
T160B	10	1.97	0.509	0.157	Black

For clip with a screw add **S** to part number, i.e. **T160S**

For copper plating add **C** to part number, i.e. **T160C**

Insulators for Standard Alligator Clips

Material: PVC

HOFFMAN PART NO.	HOFFMAN CLIP PART NO.	COLOR
T154INSB	T154	Black
T154INSBL	T154	Blue
T154INSGR	T154	Green
T154INSR	T154	Red
T154INSY	T154	Yellow
T160INSB	T160	Black
T160INSR	T160	Red
T160INSW	T160	White

