


## Charging Clips

Material: Nickle Plated Iron, 800°C

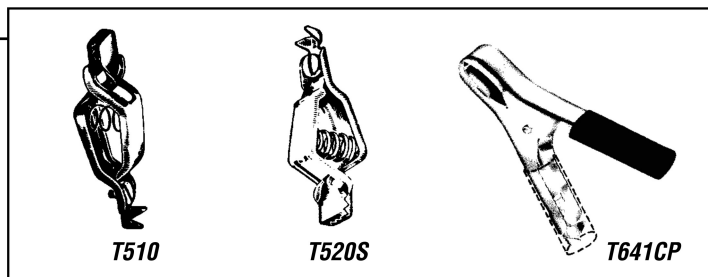

HOFFMAN PART NO.	AMPS	LENGTH	JAW SPREAD	JAW LENGTH	INSULATION	WITH SCREW
T510	10	2.0	0.43	0.39	None	N
T510SB	10	2.0	0.43	0.39	Black	Y
T510SR	10	2.0	0.43	0.39	Red	Y
T520S	20	2.5	0.67	0.51	None	Y
T520SR	20	2.5	0.67	0.51	Red	Y
T520SB	20	2.5	0.67	0.51	Black	Y
T530S	20	2.5	0.67	0.51	None	Y
T530SB	20	2.5	0.67	0.51	Black	Y
T530SBL	20	2.5	0.67	0.51	Blue	Y
T530SG	20	2.5	0.67	0.51	Green	Y
T530SR	20	2.5	0.67	0.51	Red	Y
T530SW	20	2.5	0.67	0.51	White	Y
T530SY	20	2.5	0.67	0.51	Yellow	Y
T550	50	4.1	1.50	0.51	None	Y
T550SB	50	4.1	1.50	0.51	Black	Y
T550SR	50	4.1	1.50	0.51	Red	Y
T615	15	15	0.48	0.39	None	N
T615B	15	15	0.48	0.39	Black	N
T615R	15	15	0.48	0.39	Red	N
T6410C*	100	5.91	0.676	0.866	None	N
T6410CB*	100	5.91	0.676	0.866	Black	N
T6410CR*	100	5.91	0.676	0.866	Red	N
T641CP	30	2.95	1.06	0.433	None	N
T641CPB	30	2.95	1.06	0.433	Black	N
T641CPR	30	2.95	1.06	0.433	Red	N
T641CPC*	75	2.95	1.06	0.433	None	N
T641CPCB1*	75	2.95	1.06	0.433	Black	N
T641CPCR1*	75	2.95	1.06	0.433	Red	N

\* Material is Copper, 176°C