
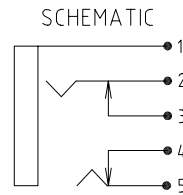
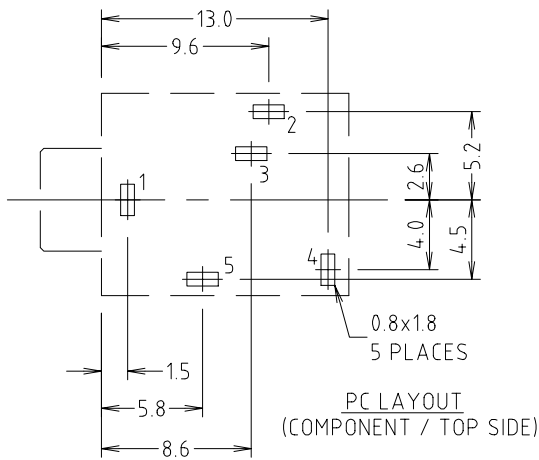
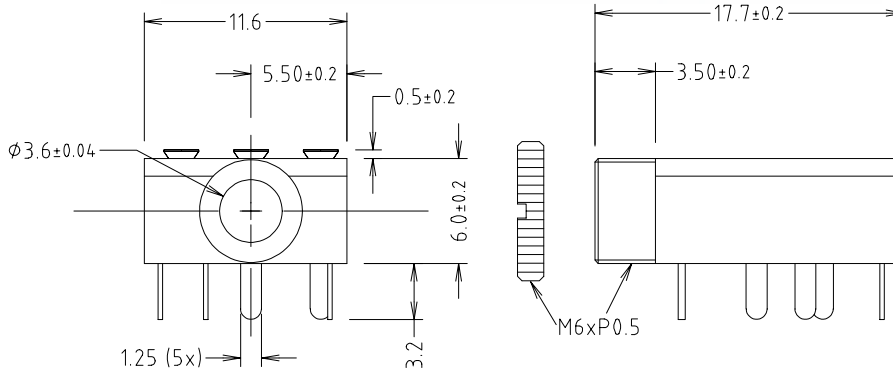


# CLIFF

## 3.5mm STEREO JACK SOCKET JYS35

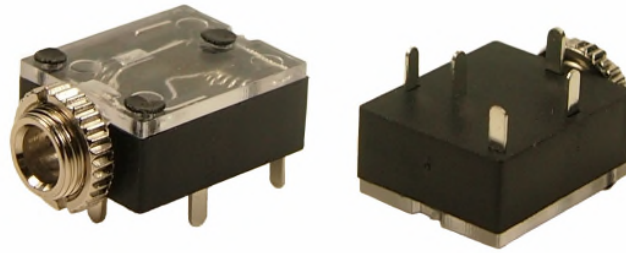

### SPECIFICATION

Current Rating 24V DC / 2A  
 Contact Resistance: 20mΩ max  
 Insulation Resistance: 100MΩ min at 240V DC  
 Dielectric Strength: 250V AC 1 minute  
 Life: 5000+

### Part No.

**FT6320** - 3.5mm STEREO JACK SOCKET WITH NUT