



**250 Tab Housings**

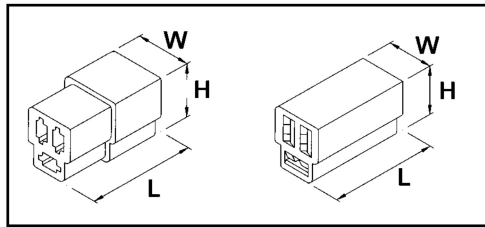

*Non-Locking*

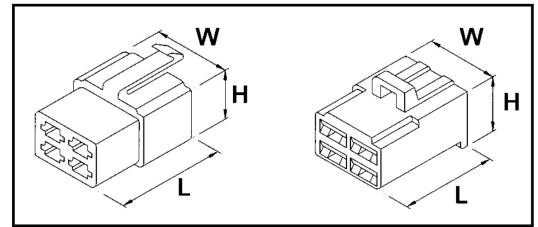


*Locking*


HOFFMAN PART NO.	DESCRIPTION	TAB	DIMENSIONS (INCHES)		
			L	H	W
F2250	Housing for 250 Female 2 Position	250	1.130	0.717	0.382
F3250	Housing for 250 Female 3 Position	250	1.130	0.784	0.646
F4250	Housing for 250 Female 4 Position	250	1.130	0.622	0.878
F6250	Housing for 250 Female 6 Position	250	1.130	0.622	1.240
F8250	Housing for 250 Female 8 Position	250	1.130	0.622	1.574
M2250	Housing for 250 Male 2 Position	250	0.965	0.650	0.272
M3250	Housing for 250 Male 3 Position	250	0.985	0.650	0.512
M4250	Housing for 250 Male 4 Position	250	0.985	0.551	0.756
M6250	Housing for 250 Male 6 Position	250	0.985	0.551	1.120
M8250	Housing for 250 Male 8 Position	250	0.985	0.551	1.470
F2250LK	Housing for 250 Female Locking 2 Position	250	1.130	0.622	0.535
F3250LK	Housing for 250 Female Locking 3 Position	250	1.130	0.784	0.646
F4250LK	Housing for 250 Female Locking 4 Position	250	1.130	0.622	0.878
F6250LK	Housing for 250 Female Locking 6 Position	250	1.130	0.622	1.555
M2250LK	Housing for 250 Male Locking 2 Position	250	0.985	0.552	0.784
M3250LK	Housing for 250 Male Locking 3 Position	250	0.985	0.650	0.512
M4250LK	Housing for 250 Male Locking 4 Position	250	0.985	0.552	0.752
M6250LK	Housing for 250 Male Locking 6 Position	250	0.985	0.552	1.510

**Pin and Socket Connectors with Housings**

**062 Pin and Socket**

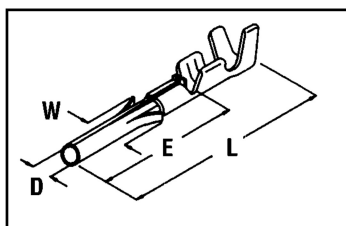

*Female Socket*

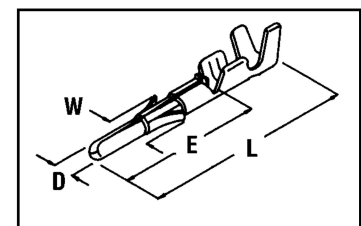

*Male Plug*

HOFFMAN PART NO.	REEL QTY	DESCRIPTION	WIRE SIZE	DIMENSIONS (INCHES)				
				L	E	W	D	UL
MPIN2218T62ST	7500	Male Pin .062 diameter Strip M Type	22-18	0.680	0.428	0.124	0.062	Y
FPIN2218T62STM	7500	Female Socket .062 Diameter Strip M Type	22-18	0.664	0.404	0.124	0.062	Y

