

## Non-Insulated Flanged Spade Terminal

### 2216 AWG Non-Insulated Flanged Spade

**Material:** Tin Plated Copper with Brazed Seam


**Maximum Electrical Current:** 18 Amps

**Material Thickness (T):** .030

**Barrel ID (d1):** .067

**Barrel OD (D):** .134

**Barrel Length (E):** .189

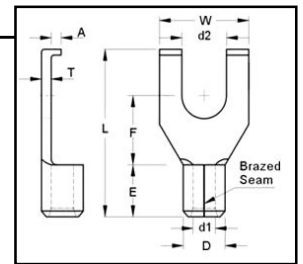

HOFFMAN PART NO.	STUD SIZE	DIMENSIONS (INCHES)					UL	TAPE MOUNTED REEL QTY	DIE FOR TAPE MOUNTED	HAND TOOL
		STUD DIAMETER d2	TONGUE WIDTH W	STUD CLEARANCE F	LENGTH L	FLANGE HEIGHT A				
2216S3B	6	0.146	0.335	0.283	0.768	0.059	Y	1000	3H2216	YHM226
2216S4B	8	0.169	0.295	0.201	0.551	0.059	Y	1000	3H2216	YHM226
2216S5B	10	0.209	0.295	0.201	0.551	0.059	Y	1000	3H2216	YHM226

### 1614 AWG Non-Insulated Flanged Spade

**Material:** Tin Plated Copper with Brazed Seam

**Maximum Electrical Current:** 30 Amps

**Material Thickness (T):** .031

**Barrel ID (d1):** .091

**Barrel OD (D):** .161

**Barrel Length (E):** .189

HOFFMAN PART NO.	STUD SIZE	DIMENSIONS (INCHES)					UL	TAPE MOUNTED REEL QTY	DIE FOR TAPE MOUNTED	HAND TOOL
		STUD DIAMETER d2	TONGUE WIDTH W	STUD CLEARANCE F	LENGTH L	FLANGE HEIGHT A				
1614S3B	6	0.146	0.335	0.283	0.709	0.059	Y	1000	3H2216	YHM226
1614S4B	8	0.169	0.335	0.283	0.709	0.059	Y	1000	3H2216	YHM226
1614S5B	10	0.209	0.335	0.283	0.709	0.059	Y	1000	3H2216	YHM226

### 1210 AWG Non-Insulated Flanged Spade

**Material:** Tin Plated Copper with Brazed Seam

**Maximum Electrical Current:** 50 Amps

**Material Thickness (T):** .039

**Barrel ID (d1):** .134

**Barrel OD (D):** .220

**Barrel Length (E):** .236

HOFFMAN PART NO.	STUD SIZE	DIMENSIONS (INCHES)					UL	TAPE MOUNTED REEL QTY	DIE FOR TAPE MOUNTED	HAND TOOL
		STUD DIAMETER d2	TONGUE WIDTH W	STUD CLEARANCE F	LENGTH L	FLANGE HEIGHT A				
1210S3B	6	0.146	0.299	0.244	0.728	0.059	Y	1000	3H1210	YHM226
1210S4B	8	0.169	0.299	0.244	0.728	0.059	Y	1000	3H1210	YHM226
1210S5B	10	0.209	0.299	0.244	0.728	0.059	Y	1000	3H1210	YHM226

