



Cable Ties

Standard Ties

Hoffman cable ties are quality product designed to provide optional application either by hand or tool. These self adjusting, self locking ties provide a permanent harness.

Cable ties are a one-piece molded mechanism with no metal barb. They combine outstanding physical properties such as light weight, abrasion resistance, toughness, high tensile strength, exceptional dielectric properties, resilience to common solvents, alkalies, dilute acids, oils and greases.

Specifications: Type 6/6 Nylon, Self-extinguishing - UL94 Flam. Class: V-2
UL Recognized component.

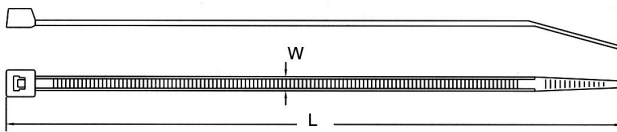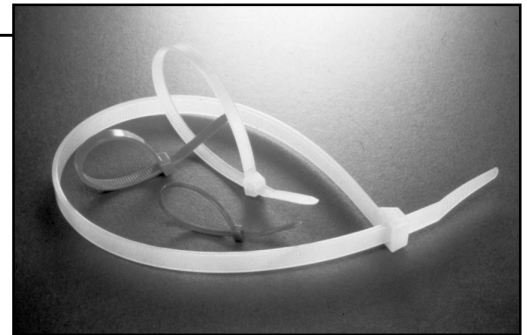

HOFFMAN PART NO	LENGTH L	WIDTH W	MAXIMUM DIAMETER (MM)	MAXIMUM DIAMETER (IN)	TENSILE STRENGTH	PACKING	UL
CT4S	4.0	0.1	25	0.98	18		Y
CT5.5S	5.5	0.1	38	1.5	18		Y
CT6.1S	6.1	0.1	45	1.77	18		Y
CT7.7S	7.7	0.1	50	1.97	18		Y
CT5.5I	5.5	0.14	37	1.46	40	Available in 100 or 1000 Pack	Y
CT7.1I	7.1	0.14	49	1.93	40		Y
CT8I	8.0	0.14	57	2.24	40		Y
CT11.8I	11.8	0.14	87	3.43	40		Y
CT14.5I	14.5	0.14	110	4.33	40		Y
CT4.7	4.7	0.19	29	1.14	50		Y
CT7.3	7.3	0.19	51	2.01	50		Y
CT11.3	11.3	0.19	83	3.27	50		Y
CT14.5	14.5	0.19	109	4.29	50		Y
CT19.7	19.7	0.19	145	5.71	50		N
CT3HD	3.0	0.30	38	1.50	120		Y
CT8HD	8.0	0.30	54	2.13	120		Y
CT11.5HD	11.5	0.30	82	3.23	120		Y
CT14.5HD	14.5	0.30	108	4.25	120		Y
CT17.7HD	17.7	0.30	133	5.24	120		N
CT17EHD	17.0	0.35	125	4.92	175	100 Pack Only	Y
CT20.7EHD	20.7	0.35	156	6.14	175		Y
CT27.6EHD	27.6	0.35	213	8.39	175		Y
CT31.4EHD	31.4	0.35	244	9.61	175		Y
CT36EHD	36.0	0.35	279	10.98	175		N
CT48EHD	48.0	0.35	380	14.96	175	N	

