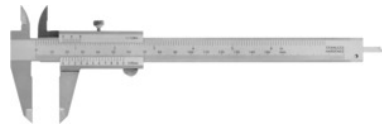


**Vernier caliper Vernier 1/20, Measuring range: 200mm****Order data**

Order number	410200 200
GTIN	4045197519269
Item class	41Z

**Description****Version:**

Satin chromium plated anti-glare reading parts.

Locking screw at the top.

Thread table: Calipers table

Standard: ISO 13385

Reversible reading: mm / inch

Depth gauge: rectangular 3.7×1.3

Packaging: Wallet

Calibration: A1

Scale divisions: 0.05 mm

Graduation: 1/20 mm

Graduation: 1/128 in

Measurement deviation E MPE:  $\pm 0.05$  mm

Jaw length: 50 mm

**Technical description**

Packaging	Wallet
Jaw length	50 mm
Measuring range	0 - 200 mm
Calibration	A1
Scale divisions	0.05 mm
Graduation	1/20 mm

Graduation	1/128 in
Reversible reading	mm / inch
Standard	ISO 13385
Depth gauge	rectangular 3.7×1.3
Depth gauge available	yes
Measurement deviation E MPE	± 0.05 mm
Locking	Locking screw at top
Measurement technology	analogue
Material	Stainless steel, INOX
all parts	hardened
Thread table	Calipers table
Type of product	Universal calipers

## Services

Calibration Calipers / depth gauges maximum measuring range 200 mm	011030 200
Labelling laser-etched Type	018940
DAkkS calibration Calipers / depth gauges maximum measuring range 200 mm	011050 200
DAkkS calibration Calipers / depth gauges maximum measuring range 200 mm	021010 200
Calibration Calipers / depth gauges maximum measuring range 200 mm	021000 200